

Data sheet

SmartConnect Patchpanel 12 ports MC module

Page 1/4


P/N

130927-1200-E


EAN 4251394635439

2020/07/16

Illustrations

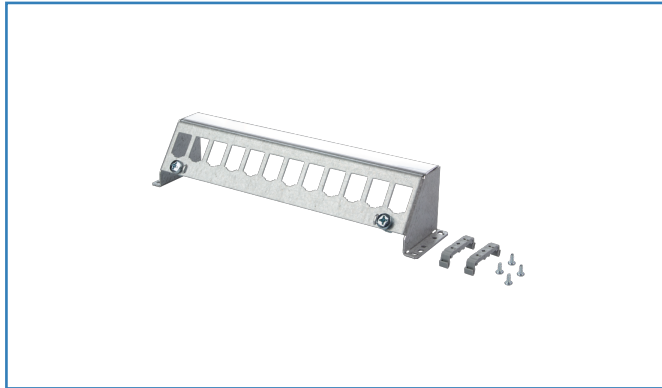

Dimensional drawing

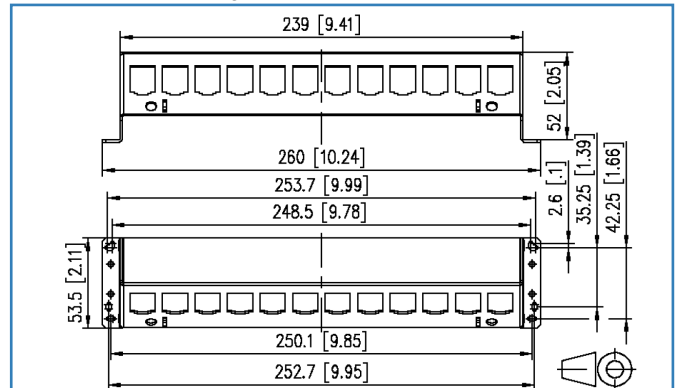

See enlarged drawings at the end of document

Product specification

- empty module holder for receiving data, KOAX and fiber optic modules
- mounting type: module
- mounting on standard rail (TH35) or on support frame or mounting plate screwable
- consisting of 1 module holder made of bent sheet metal and 2 milled plastic brackets universally applicable for all variants
- mounting the plastic brackets on standard rail and perforated metal plate
- functional equipotential bonding acc. to DIN EN 50310 (VDE0800-2-310) with 2 screw fastenings via grounding screw M6x10 with nut and lock washer possible
- 1 labeling strip on module holder
- variants: 12, 16, 24 ports



SmartConnect Patchpanel 12 ports MC module

P/N

130927-1200-E

EAN 4251394635439

2020/07/16

Technical Data

General Data	
Design	patch panel
Mounting style	standard rail TH35, perforated metal plate
Color	gray
Dimensions	
Dimension (L x W x H)	260 mm x 53.5 mm x 53.5 mm
Dimension (L x W x H)	10.236 in. x 2.106 in. x 2.106 in.
Weight	236 g
Modularity	yes
Labeling option	labeling strip on module holder
Connections/interfaces	
Number of ports interface 1	12
Number of equipped ports interface 1	0
Cable access/outlet	45° upwards
Ground connection	grounding screw M6x10 with nut and lock washer
Mechanical data	
Cut-out	module
Materials and material properties	
Material - Housing	aluminium-zinc sheet
Material - Mounting	PVC
RoHS	compliant
Classifications	
ETIM 7.0	EC002006
Packing details	
Type of packaging	1 pc(s) / plastic bag
Packaging unit - Weight (gram)	246 g
Packaging unit - Weight (pound)	0.54 lb
Packaging dimension	54 mm x 260 mm x 65 mm
Packaging dimension	2.12 in. x 10.24 in. x 2.56 in.

SmartConnect Patchpanel 12 ports MC module

P/N

130927-1200-E

EAN 4251394635439

2020/07/16

Accessories

P/N	Designation
1308450233-E	Patch cord Cat.6 _A AWG 26 0.2 m gray
1308450333-E	Patch cord Cat.6 _A AWG 26 0.3 m gray
1308450533-E	Patch cord Cat.6 _A AWG 26 0.5 m gray
1308451033-E	Patch cord Cat.6 _A AWG 26 1.0 m gray
13084V0300-E	Patch cord Cat.6 Ultraflex500 VoIP AWG 26 0.3 m black
13084V0333-E	Patch cord Cat.6 Ultraflex500 VoIP AWG 26 0.3 m gray
13084V0388-E	Patch cord Cat.6 Ultraflex500 VoIP AWG 26 0.3 m white
13084V0500-E	Patch cord Cat.6 Ultraflex500 VoIP AWG 26 0.5 m black
13084V0533-E	Patch cord Cat.6 Ultraflex500 VoIP AWG 26 0.5 m gray
13084V0588-E	Patch cord Cat.6 Ultraflex500 VoIP AWG 26 0.5 m white
13084V1000-E	Patch cord Cat.6 Ultraflex500 VoIP AWG 26 1.0 m black
13084V1033-E	Patch cord Cat.6 Ultraflex500 VoIP AWG 26 1.0 m gray
13084V1088-E	Patch cord Cat.6 Ultraflex500 VoIP AWG 26 1.0 m white
130898-00-I	BLIND module light gray
130898-00-RW-I	BLIND module pure white
130898-01-I	COAX modul F jack / F jack
130898-02-I	COAX modul IEC jack / F jack
130898-03-I	COAX modul IEC plug / F jack
130908-I-B1	UAE modul Cat.5e white
130909-I	UAE modul Cat.6 jack T568A white
130910-I	E-DAT modul Cat.6 _A 8(8) jack, T568A
1309A0-I	E-DAT modul Coupler 8(8) 180° Cat.6
130A11-29-I	UAE modul 8(8) Cat.6 _A black
130A11-I	UAE modul 8(8) Cat.6 _A white
130B11-25-E	25Gmodul
130B11-E	C6 _A modul 180° jack
15091071-I	OpDAT modul LC-D (ceramic, blue) SM
15091072-I	OpDAT modul LC-D (ceramic, aqua) MM
15091075-I	OpDAT modul LC-D (ceramic, violet) MM
15091076-I	OpDAT modul LC-D APC (ceramic, green) SM
1509107M-I	OpDAT modul LC-D (ceramic, lime green) OM5

Illustrations

Dimensional drawing

