

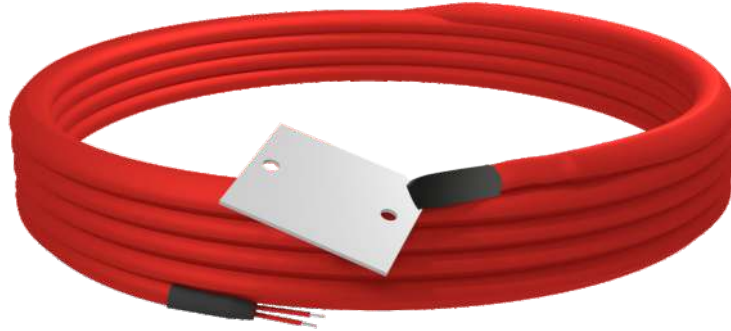


► (RT) Standard Bayonet Type
RT-M06-L050 x 050-K02 T+T

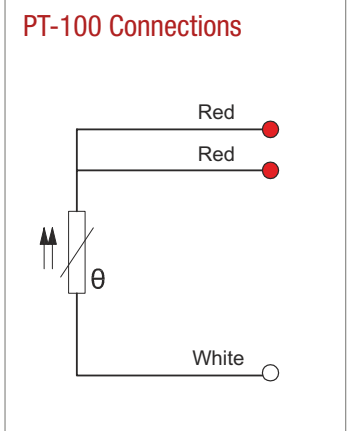

Max. operating temperature : -50 °C / +260 °C
Standard cable types : Teflon + Teflon
Sensor type : DIN/EN60751 Class "B" 1xPT-100
Protection tube material : Aluminum

► Technical drawing

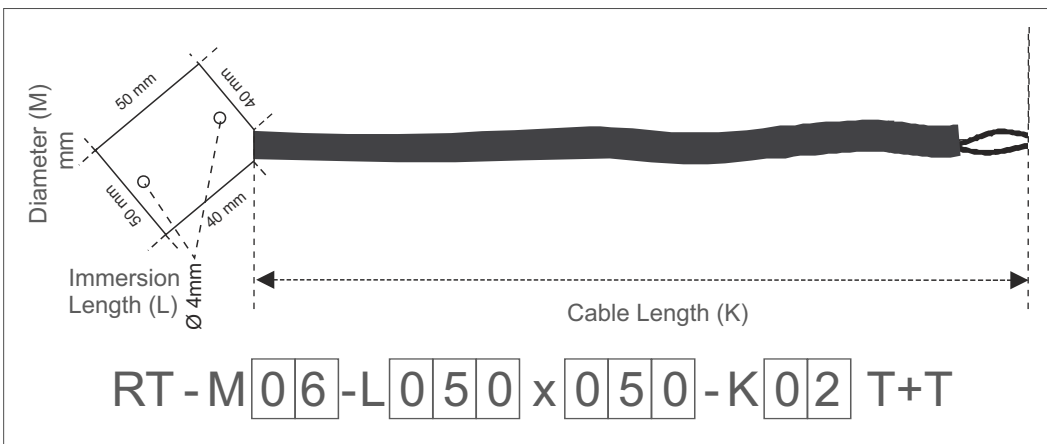

Diameter (M) : 6 mm
Immersion Length (L) : 50 x 50 mm
Cable Length (K) : 2 meter