


## Data Sheet

### MECHANICAL BUZZER

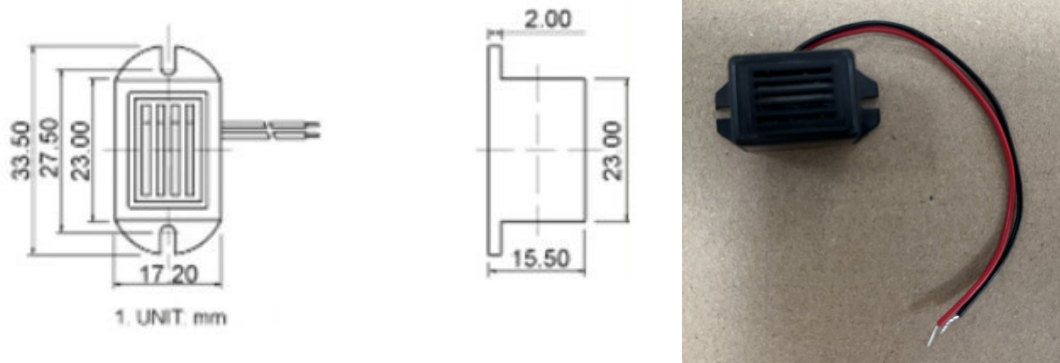

### Technical data

Rated voltage	4.5V/DC
Operating voltage	3V-7V/DC
Max Rated current	25mA at 4.5VDC
Min Sound Pressure Level	75dB at 4.5VDC/20cm
Resonant Frequency	400±100Hz
Operating temperature	-20°C to +60°C
Storage Temperature	-30°C to +70°C
Housing material/color	ABS/BLACK
Weight	7.6 g
Length of open-end wire	10 cm
Sound signal type	Continuous acoustic signal