

Product Datasheet

Rechargeable

eneloop AA



BK-3MCDE




IEC Dimensions (mm)		
Dimension	Maximum	Minimum
A	50,4	
B	14,35	

Name	BK-3MCDE
Size	AA
Type	NiMH rechargeable
Nominal Voltage	1.2 V
Made in	Japan
Average weight	28 g
Capacity (minimum)	2000 mAh
Ambient temp. charge	0°C - 40°C
Ambient temp. discharge	-20°C - 50°C
Internal impedance (after discharge to E.V.=1.0V)	Approx. 25mΩ (at 1000Hz)

Typical characteristics

Charge

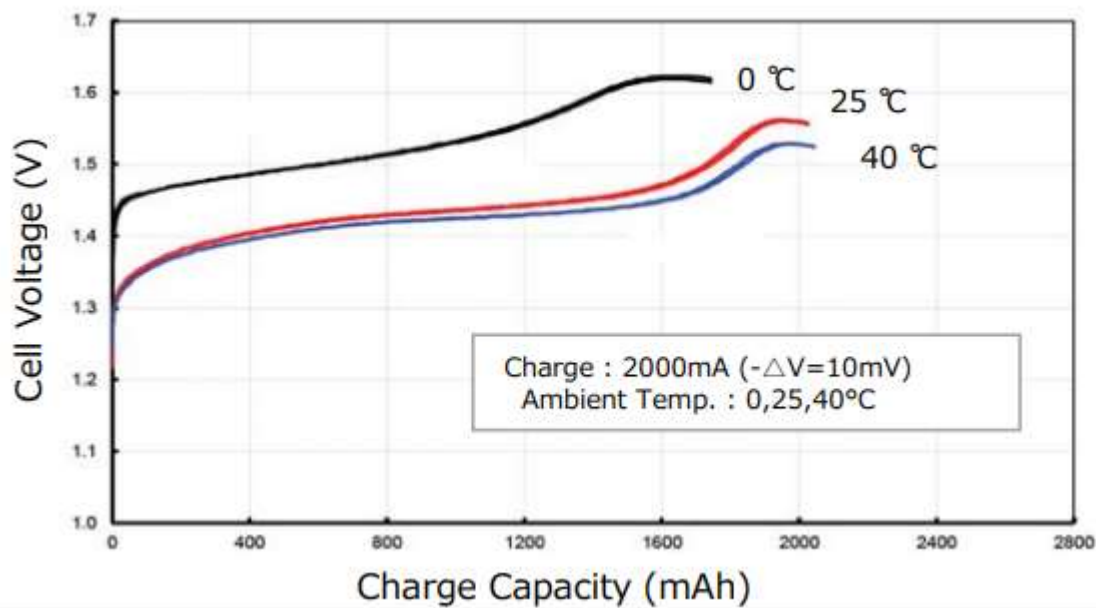

Discharge

