


## Data Sheet

### Push in fitting, Male Elbow

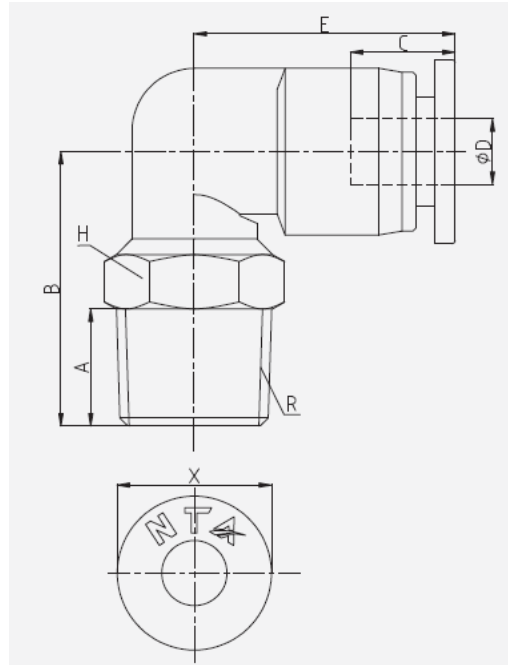

- Pressure range: 0 -10 bar
- Negative pressure: -1 bar (10 Torr)
- Max. pressure: 15 bar
- Temperature range: -10 – 80 °C

Item no.	Model no.	D	R	A	E	B	H	X	C
2615619	GPL6-01	6	R1/8	7.5	20.5	22	10	11.8	16.7
2615620	GPL6-02	6	R1/4	9.5	20.5	22.8	14	11.8	16.7
2615621	GPL8-01	8	R1/8	7.5	23.3	26.9	12	13.8	19.1
2615622	GPL8-02	8	R1/4	9.5	23.3	24	14	13.8	19.1
2615623	GPL10-02	10	R1/4	9.5	27	31	17	16.8	21.2
2615624	GPL10-03	10	R3/8	10.5	27	31	17	16.8	21.2