


Data Sheet

Push in fitting, Union - Elbow

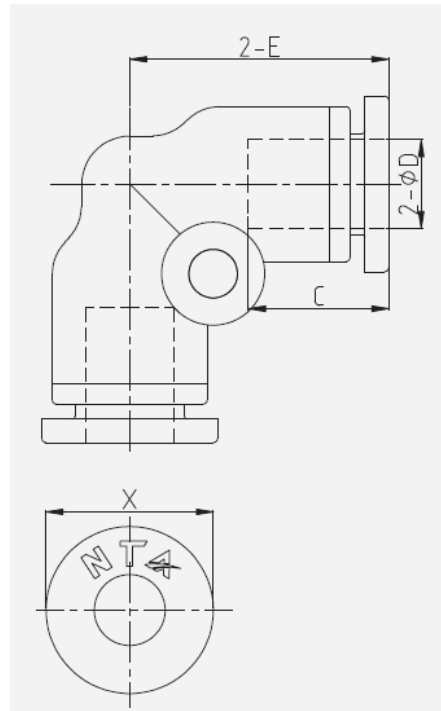

- Pressure range: 0 -10 bar
- Negative pressure: -1 bar (10 Torr)
- Max. pressure: 15 bar
- Temperature range: -10 – 80 °C

Item no.	Model no.	D	E	d	C	X
2615642	PV4	4	17.9	3.3	15.3	9.9
2615643	PV6	6	20.1	3.2	16.7	11.8
2615644	PV8	8	23.5	3.3	19.1	13.8
2615645	PV10	10	26.8	4.3	21.2	16.8
2615646	PV12	12	30.8	4.3	24.4	19.8