


Data Sheet

Push in fitting, Bulkhead Union

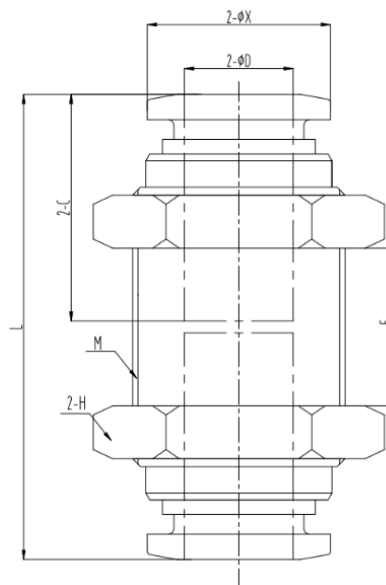

- Pressure range: 0 -10 bar
- Negative pressure: -1 bar (10 Torr)
- Max. pressure: 15 bar
- Temperature range: -10 – 80 °C

Item no.	Model no.	D	M	E	H	L	X	C
2615657	PM4	4	M12	13	14	31	9.9	15
2615658	PM6	6	M14	13.2	17	32.7	11.8	15.8
2615659	PM8	8	M16	12	19	35.1	13.8	17.1