


## Data Sheet

### Speed controller, Union – Straight

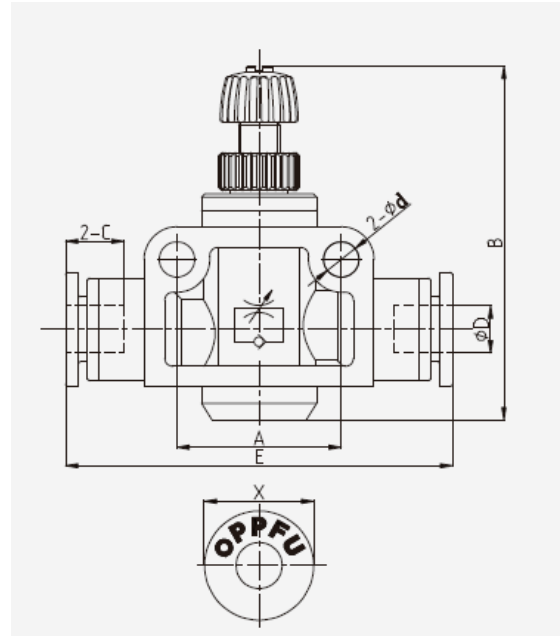

- Pressure range: 0 - 8 bar
- Negative pressure: -1 bar (10 Torr)
- Temperature range: 0 – 60 °C

Item no.	Model no.	D	d	A	B		E	C	X
					min	max			
2615701	SA4	4	3.2	14	28	31	39.5	14.4	9.9
2615660	SA6	6	4.3	20	40.7	47.5	47.1	15.5	11.8
2615661	SA8	8	4.3	22	44.1	51.8	52	16.8	13.8