


Data Sheet

G thread Speed Controller, Male Elbow

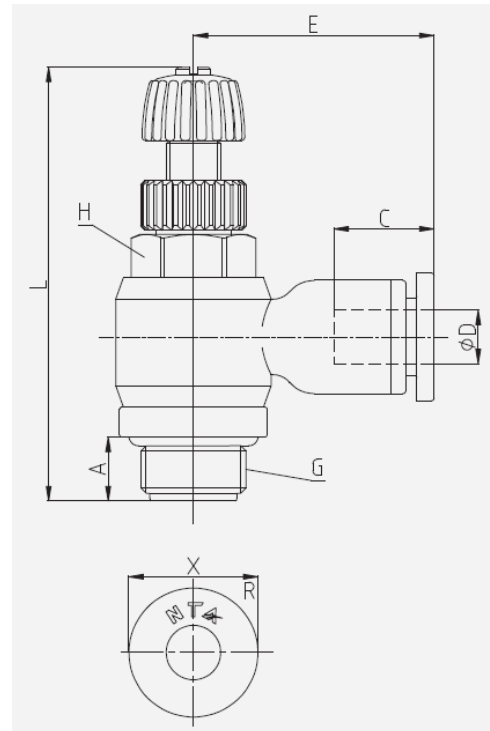

- Pressure range: 0 - 8 bar
- Negative pressure: -1 bar (10 Torr)
- Temperature range: 0 – 60 °C

Item no.	Model no.	D	G	A	H	E	C	X	L	
									min	max
2615694	SL6-G01	6	G1/8	6	10	229	15.4	11.8	37.5	44.3
2615695	SL6-G02	6	G1/4	8.3	14	24.9	15.4	11.8	43.7	51.3
2615696	SL8-G01	8	G1/8	6	10	25.3	17.3	13.8	37.5	44.3
2615697	SL8-G02	8	G1/4	8.3	14	28.4	18.3	13.8	43.7	51.3
2615698	SL8-G03	8	G3/8	9.5	19	29.3	18.3	13.8	52.7	59.5