

# EAO – Your Expert Partner for Human Machine Interfaces

45-2C36.1920.000 - Emergency-stop switch actuator, foolproof EN IEC 60947-5-5

## 45-2C36.1920.000 - Emergency-stop switch actuator, foolproof EN IEC 60947-5-5



*Attention: The preview is based on a sample product. This can differ from your current configuration.*

### Mounting

Mounting cut-out Design Ø 22.5 mm raised

### Front

Front shape round  
Front dimension Ø 40 mm  
Front ring material Plastic  
Front ring colour black

### Other Attributes

Weight 0.046 kg

### Operating-/Indication part

Lens optics opaque  
Lens material Plastic  
Lens colour red  
Lens profile Mushroom  
Lens illumination non-illuminative

### IP-Rating

Front protection IP66, IP67, IP69K

### Actuator

Switching action Maintained  
Housing material Plastic

### Switching element

max. number of switching elements 6


### Function

Emergency stop switch


# EAO – Your Expert Partner for Human Machine Interfaces

45-2C36.1920.000 - Emergency-stop switch actuator, foolproof EN IEC 60947-5-5


## Dimensions

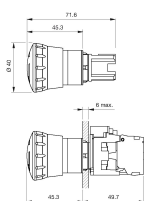

## Mounting cut-outs

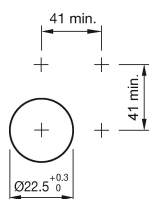

## Wiring diagram

 

## Additional information

Application as per DIN EN ISO 13850 and EN 60204-1  
twist to release

## Legend

Switching action: C = Maintained