


## Data Sheet

### Strain relief metal spiral cable gland

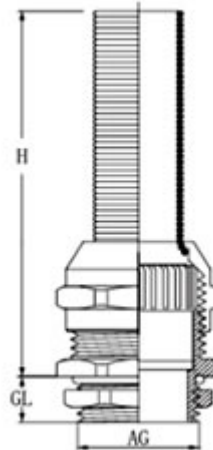

Item No.	Thread	Range	GL ± 0.2 mm	Thread O. D. (AG)	H ± 1 mm	Spanner Size	Material
2618360	M12x1.5	3-6.5	7	11.72	53	14	Brass nickel plated
2618361	M16x1.5	4-8	6	15.85	66	17/18	Brass nickel plated
2618362	M18x1.5	5-10	8	17.65	77	20	Brass nickel plated
2618363	M20x1.5	6-12	8	19.70	89	22	Brass nickel plated
2618364	M22x1.5	10-14	8	21.71	97	24	Brass nickel plated
2618365	M25x1.5	13-18	9	24.77	112	30/27	Brass nickel plated
2618366	M30x1.5	13-18	9	29.73	113	30/32	Brass nickel plated

Material: Nickel-plated brass

Claw: PA66 (Nylon), UL94-V2

Hermetic seal: NBR, Silicone rubber

Protection degree: IP68

Temperature: Static state -40 - 100°C, Short time to 120°C