


Data Sheet

Metal breathable valve

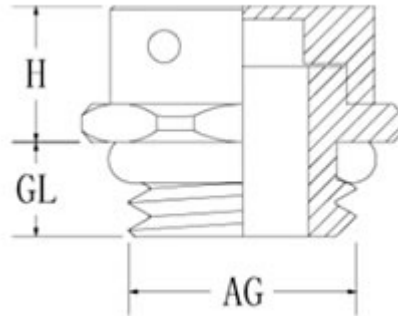

Item No.	Size	Air permeability	Material	Thread Diameter (AG)	Thread Length (GL) ±0.2 mm	TOTAL Length ±0.2 mm	Spanner Size
2618367	M5X0.8	≥ 300ml/min/@70mbar	Brass Nickel Plated	4.90	7	15	10/8
2618368	M6X1	≥ 300ml/min/@70mbar	Brass Nickel Plated	5.75	7	15	10
2618369	M8X1.25	≥ 800ml/min/@70mbar	Brass Nickel Plated	7.80	7	15.5	12
2618370	M10X0.75	≥ 1200ml/min/@70mbar	Brass Nickel Plated	9.82	8	17	14
2618371	M12X1.5	≥ 1500ml/min/@70mbar	Brass Nickel Plated	11.80	8.5	17.5	16/14
2618372	M16X1.5	≥ 1700ml/min/@70mbar	Brass Nickel Plated	15.71	10	19	20/18
2618373	M20X1.5	≥ 1700ml/min/@70mbar	Brass Nickel Plated	19.75	10	19	22
2618374	UNF 5/8"	≥ 1700ml/min/@70mbar	Brass Nickel Plated	15.63	10	19	20/18

Material: Nickel-plated brass

Protection degree: IP68

Temperature: Static state -40 - 100°C, Short time to 120°C

Water inlet pressure: > 5 bar