


## Data Sheet

### Nylon breathable valve

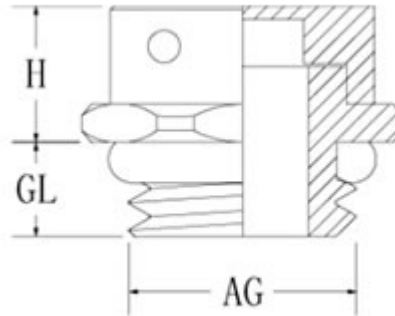

Item No.	Size	Air permeability	Material	Thread Diameter (AG)	Thread Length (GL) ±0.5 mm	TOTAL Length ±0.5 mm	Spanner Size
2618375	M5X0.8	≥ 600ml/min/@70mbar	PA66	4.70	7	13	12/8
2618376	M6X1	≥ 600ml/min/@70mbar	PA66	5.63	7	13	12/10
2618377	M8X1.25	≥ 600ml/min/@70mbar	PA66	7.65	10	18	17/13
2618378	M10X1.5	≥ 1500ml/min/@70mbar	PA66	9.69	10	18	17/15
2618379	M12X1.5	≥ 1500ml/min/@70mbar	PA66	11.72	10	18	17/16
2618380	M16X1.5	≥ 4500ml/min/@70mbar	PA66	15.79	10	18	22
2618381	M20X1.5	≥ 4000ml/min/@70mbar	PA66	19.56	10	18	27
2618382	M24X1.5	≥ 7000ml/min/@70mbar	PA66	23.64	15	24.5	30
2618383	M40X1.5	≥ 8500ml/min/@70mbar	PA66	39.75	15	24.5	56/52

Material: Nylon PA66

Protection degree: IP68

Temperature: Static state -40 - 100°C, Short time to 120°C

Water inlet pressure: > 5 bar