

## Han Domino Pneumatic cube (MF.1)

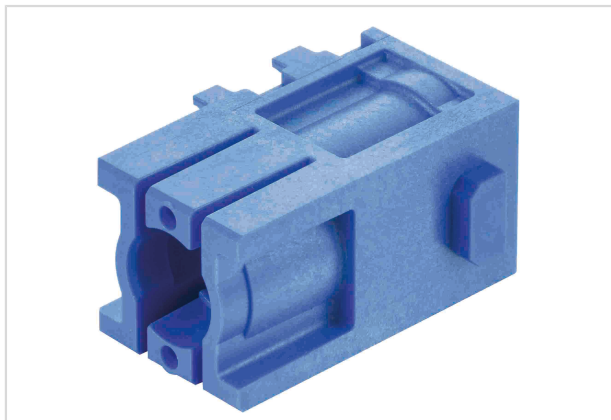


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 931 1001
Specification	Han Domino Pneumatic cube (MF.1)
HARTING eCatalogue	<a href="https://b2b.harting.com/09149311001">https://b2b.harting.com/09149311001</a>

### Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® Domino Pneumatic Cube
Size of the module	Domino module
Description of the module	Small tab

### Version

Gender	Male Female
Number of contacts	1
Details	Please order contacts separately.

### Technical characteristics

Limiting temperature	-40 ... +85 °C
Mating cycles	≥10,000

### Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	Blue
Material flammability class acc. to UL 94	V-0



**Pushing Performance**  
Since 1945

## Specifications and approvals

Specifications	EN 60664-1 IEC 61984
----------------	-------------------------

## Commercial data

Packaging size	2
Net weight	0.01 kg
Country of origin	Romania
European customs tariff number	85389099
eCl@ss	27440220 Module for industrial connectors (pneumatic)