

Han Domino Pneumatic cube (MF.2)

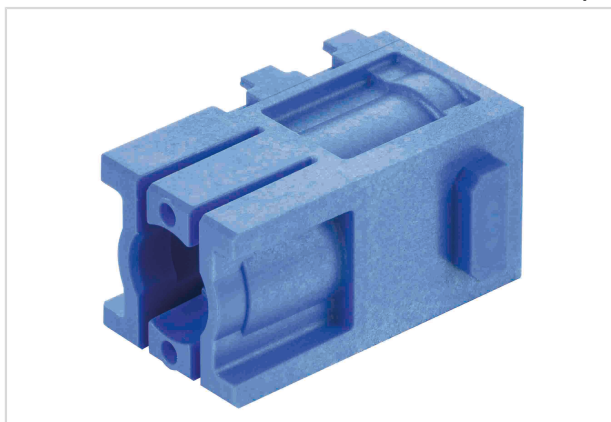


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 931 2001
Specification	Han Domino Pneumatic cube (MF.2)
HARTING eCatalogue	https://b2b.harting.com/09149312001

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® Domino Pneumatic Cube
Size of the module	Domino module
Description of the module	Large Tab

Version

Gender	Male Female
Number of contacts	1
Details	Please order contacts separately.

Technical characteristics

Limiting temperature	-40 ... +85 °C
Mating cycles	≥10,000

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	Blue
Material flammability class acc. to UL 94	V-0



Pushing Performance
Since 1945

Specifications and approvals

Specifications	EN 60664-1 IEC 61984
----------------	-------------------------

Commercial data

Packaging size	2
Net weight	0.01 kg
Country of origin	Romania
European customs tariff number	85389099
eCl@ss	27440220 Module for industrial connectors (pneumatic)