


## Data Sheet

---

### BA15S bulb socket

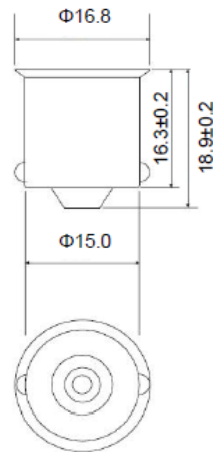

Unit: mm

#### Technical data:

Lamp bulb type: BA15S

Material: Brass

Plating: Nickel

Voltage rating: 50 VAC/ 75 VDC max.

Operating temperature: -10 to 105°C

Storage temperature: -10 to 85°C

Max. power of lamp: 25W