



## Data Sheet

### Piezo buzzer (wire), 85dB

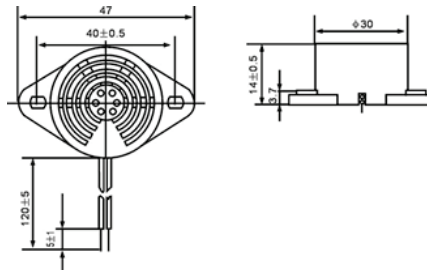

Unit: mm

#### Frequency response:

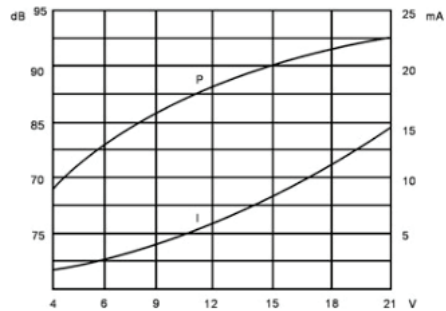

#### Technical data:

Rated voltage	12VDC
Operating voltage	3V-24VDC
Max Rated current	10mA at 12VDC
Min Sound Pressure Level	85dB at 12VDC/20cm
Resonant Frequency	3500±500Hz
Tone sound	Continuous
Operating temperature	-20°C to +60°C
Storage Temperature	-20°C to +60°C
Housing material/color	ABS/black
Weight	8g