



# Data Sheet

## Piezo buzzer (wire), 95dB

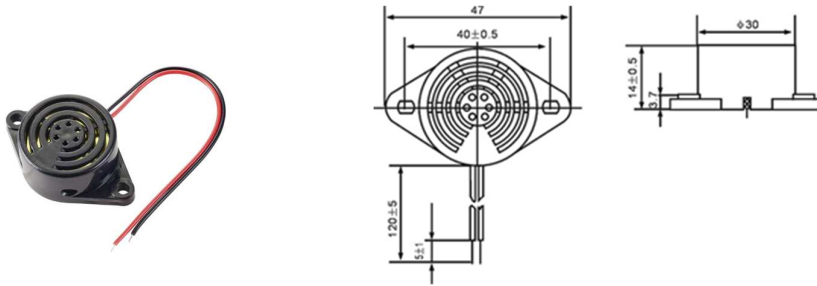

Unit: mm

### Frequency response:

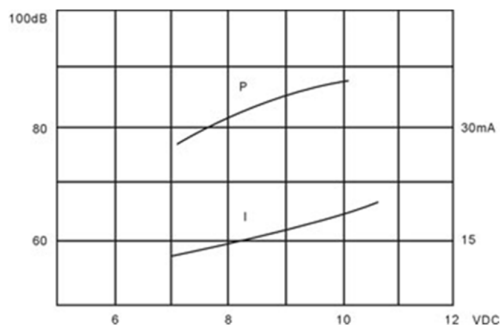

|                          |                    |
|--------------------------|--------------------|
| Rated voltage            | 12VDC              |
| Operating voltage        | 3V-24VDC           |
| Max Rated current        | 10mA at 12VDC      |
| Min Sound Pressure Level | 95dB at 12VDC/30cm |
| Resonant Frequency       | 3300±500Hz         |
| Tone sound               | Continuous         |
| Operating temperature    | -20°C to +80°C     |
| Storage Temperature      | -20°C to +80°C     |
| Housing material/color   | ABS/black          |
| Weight                   | 8g                 |