
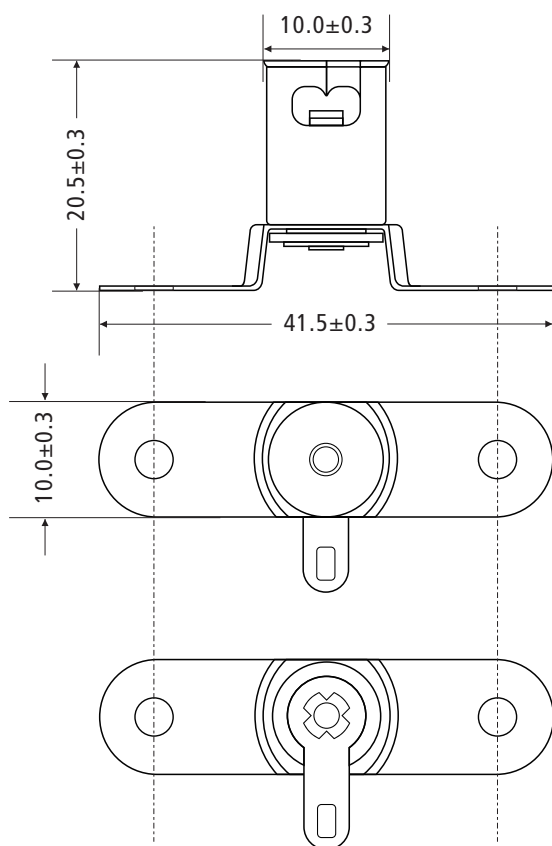


BA9s Lamp Bulb Socket

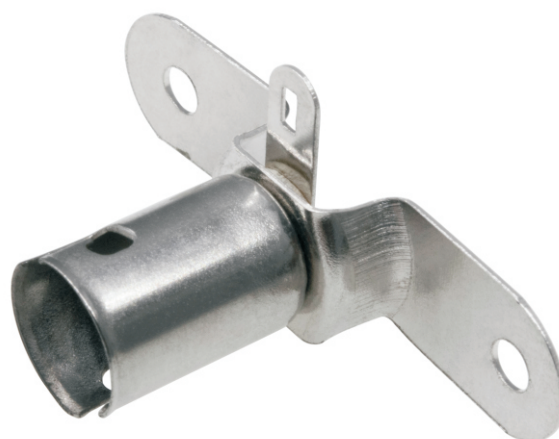

Specification

Lamp bulb type: BA9s

Material: Brass

Plating: Nickel

Voltage rating: 24V (DC)

Current rating: 3A max.

Operating temperature: -10 to 105°C

Operation humidity: $>85\%RH$

Storage temperature: -10 to 85°C

Operation humidity: $>95\%RH$