


Data Sheet

E10 bulb holder with screw mounting and soldering terminal

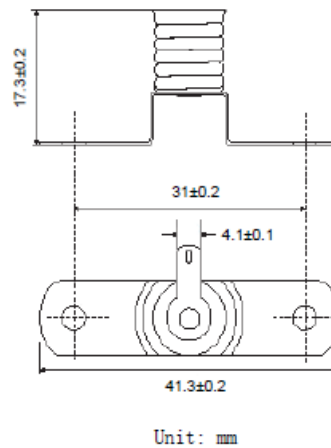

Technical data:

Lamp (Bulb) type: E10

Material: Brass

Plating: Nickel

Voltage rating: 50 VAC/ 75 VDC max.

Operating temperature: -10 to 105°C

Storage temperature: -10 to 85°C