


## Data Sheet

---

### E10 bulb holder with solder lead

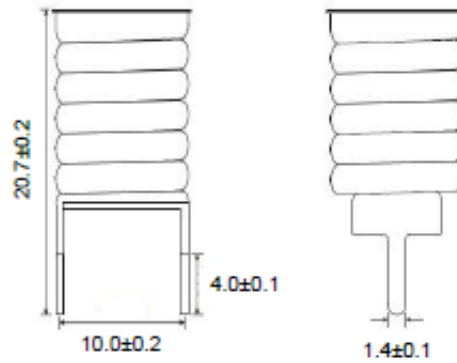

Unit: mm

#### Technical data:

Lamp (Bulb) type: E10

Material: Brass

Plating: Nickel

Voltage rating: 50 VAC/ 75 VDC max.

Operating temperature: -10 to 105°C

Storage temperature: -10 to 85°C