



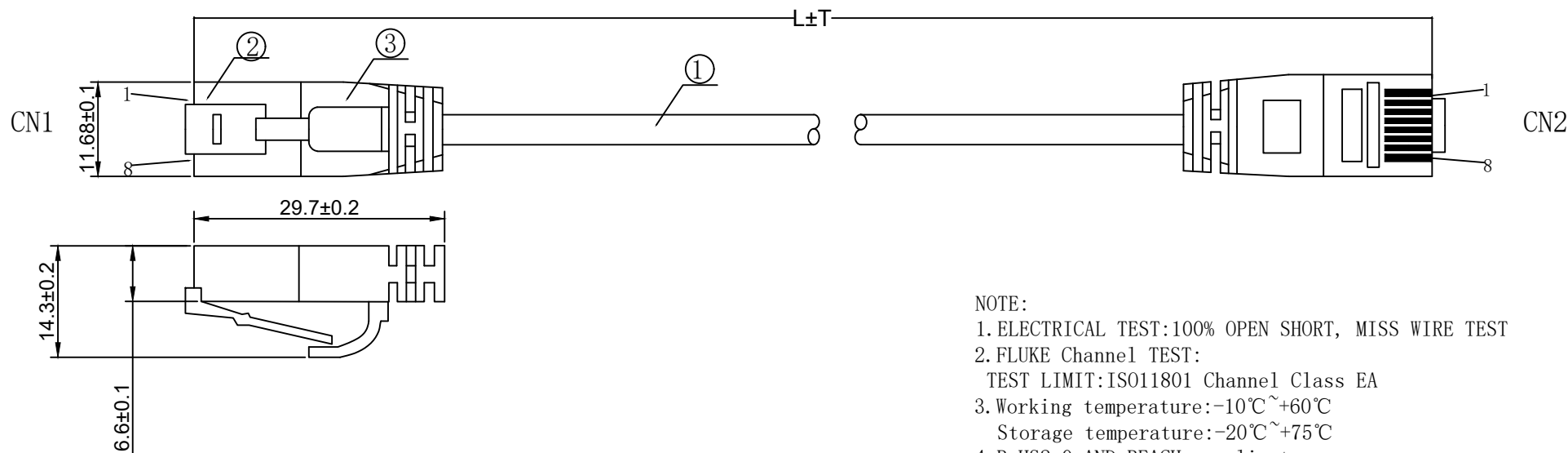

NOTE:

- ELECTRICAL TEST:100% OPEN SHORT, MISS WIRE TEST
- FLUKE Channel TEST:
TEST LIMIT:ISO11801 Channel Class EA
- Working temperature:-10℃~+60℃
Storage temperature:-20℃~+75℃
- RoHS2.0 AND REACH compliant
- Spray WORD:CAT6A U/FTP 4x2x32AWG/7 Ultraflex LSZH-TPE ISO11801 & EN50173 & ANSI/TIA568C.2
- Minimum of the bending radius is 15mm(Suitable for all meters)

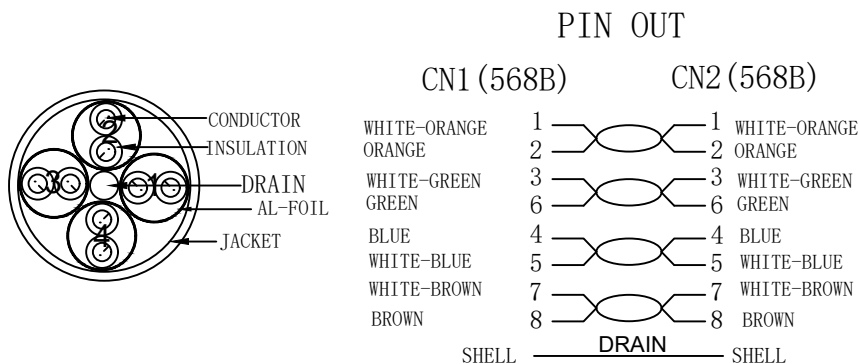

MATERIAL LIST

③	OVER MOLD	75A PVC WHITE(RAL9003)	2	
②	PLUG	RJ45 8P8C Shielded Plug, PIN GOLD PLATED 3u",THE SHELL PLATED NICKEL, COLOUR:TRANSPARENT	2	
①	CABLE	CAT.6A U/FTP CABLE (32AWG BC*1P+AL-FOIL)*4+DRAIN JACKET:ULTRAFLEX LSZH-TPE/WHITE (RAL9003), OD:3.6±0.2MM	1	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT'Y	REMARK
		NEW	2022-07-01	A
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.

Item NO.	Length (mm)
21.44.1698	150±10
21.44.1699	300±10
21.44.1700	500±20
21.44.1701	1000±20
21.44.1704	1500±30
21.44.1702	2000±30
21.44.1703	3000±50
21.44.1705	5000±100

DESC.

ROLINE GREEN Cat.6A U/FTP Patch cord 10G Slim Type Ultraflex LSZH-TPE,white

SECOMP