


## Cable Clip Set 50 pcs

No.: 22CA144 ... 22CA159

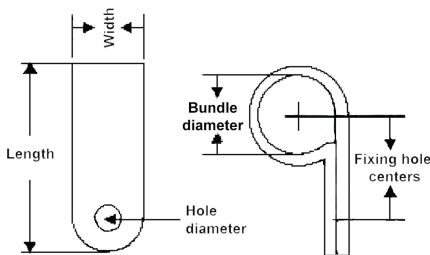

High quality cable clips – easy to use. Only need to put the wire into the round hole and tighten the screw. Fast and convenient. Made of best Polyamide 6.6, aging resistant, heat resistant and UV-safe.

**Technical data:** Color: natural or black • Material: Polyamide 6.6 • Temp.-range: -40 ... 85 °C • Flammability: UL94 V2 • UV resistant • corrosion-resistant • Content: 50 pcs set.

Part No.	EAN	Bundle diameter max.	Fixing hole centers	Length (footprint)	Width (footprint)	Hole diameter	Color
22CA144	4260732281238	3.3 mm	9.5 mm	16.5 mm	9.5 mm	4.2 mm	Natural
22CA145	4260732281245	5.3 mm	11.3 mm	18.5 mm	9.5 mm	4 mm	Natural
22CA146	4260732281252	6.4 mm	11.5 mm	21 mm	9.5 mm	4.3 mm	Natural
22CA147	4260732281269	8.4 mm	11.5 mm	21.7 mm	9.5 mm	4 mm	Natural
22CA148	4260732281276	10.4 mm	12.5 mm	25 mm	9.5 mm	4.4 mm	Natural
22CA149	4260732281283	13.2 mm	14.5 mm	25.5 mm	9.5 mm	4.3 mm	Natural
22CA150	4260732281290	16 mm	17 mm	30.5 mm	9.4 mm	4 mm	Natural
22CA151	4260732281306	19 mm	19.5 mm	35.5 mm	12 mm	4.7 mm	Natural
22CA152	4260732281313	3.3 mm	9.5 mm	16.5 mm	9.5 mm	4.2 mm	Black
22CA153	4260732281320	5.3 mm	11.3 mm	18.5 mm	9.5 mm	4 mm	Black
22CA154	4260732281337	6.4 mm	11.5 mm	21 mm	9.5 mm	4.3 mm	Black
22CA155	4260732281344	8.4 mm	11.5 mm	21.7 mm	9.5 mm	4 mm	Black
22CA156	4260732281351	10.4 mm	12.5 mm	25 mm	9.5 mm	4.4 mm	Black
22CA157	4260732281368	13.2 mm	14.5 mm	25.5 mm	9.5 mm	4.3 mm	Black
22CA158	4260732281375	16 mm	17 mm	30.5 mm	9.4 mm	4 mm	Black
22CA159	4260732281382	19 mm	19.5 mm	35.5 mm	12 mm	4.7 mm	Black