
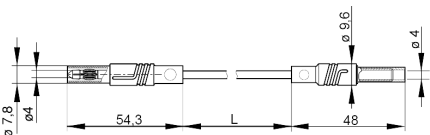


Measuring leads

MAL S GG-B 50/2,5



Product	MAL S GG-B 50/2,5
description	Safety adapter test lead according to IEC 61010 with 4 mm safety plug straight outlet and 4 mm safety socket on the other end. Highly flexible, double insulated stranded lead, shatter-proof grip sleeve. Built in color indicator for easy identification of insulation damages.
operating instruction	BA453
article-no. / *colour	9340451xx  00 black 01 red 02 blue 03 yellow 04 green 88 yellow green <div style="text-align: right;">Ni</div>
drawing	
technical data	
rated voltage ⁽¹⁾	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current ⁽¹⁾ (consider derating curve)	32 A
material plug	brass, nickel plated
material socket	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽²⁾	-15 °C to +70 °C
inflammability class acc. to UL 94 (only valid for basic material of housing)	V-2
cable length	50 cm
conductor size	2,5 mm ²
cable material	PVC

4 mm safety system

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 13.06.2022