

# VOLTCRAFT

## VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

## AAA ALKALINE BATTERY



Item No.:	Qty.
2623585	1
2542829	4
2813278	10
2533753	24
2377793	40

### TECHNICAL DATA


Type:	AAA LR03
Classification:	Non-rechargeable
Chemical system:	Alkaline
Nominal voltage:	1.5 V
Terminals:	Flat
Weight (approx.):	11.7 g
Capacity	1350 mAh (10 mA, 24 h/d , 20 °C, e.v. = 0.8 V)
Operating conditions:	-18 to +50 °C +10 to +35 °C (recommended)
Storage conditions:	+10 to +25 °C (max. 30 °C), <60 % RH
Heavy metals:	No added mercury (Hg), Cadmium (Cd), or Lead (Pb)
Compliant to:	IEC 60086-1 IEC 60086-2 IEC 60086-5

\*For performance and safety, observe the operating / storage conditions.




### PERFORMANCE CHARACTERISTICS

#### DISCHARGE

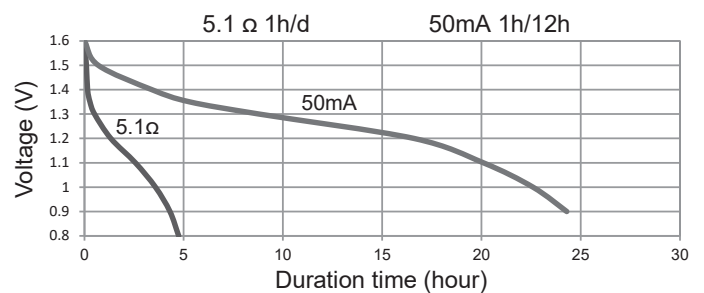

#### DIMENSIONS (mm)

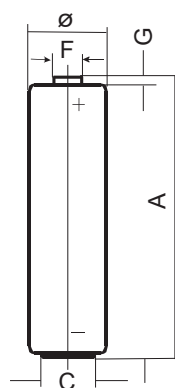

Dimension	Min.	Max.
Ø	9.8	10.5
A	43.5	44.5
C	4.3	-
F	-	3.8
G	0.8	-

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

Copyright 2024 by Conrad Electronic SE. \*2377793,2533753,2542829,2623585,2813278\_v1\_1024\_02\_ds\_en