


Item no.: 2623964

Data Sheet

BA15D bulb socket



Drawing:

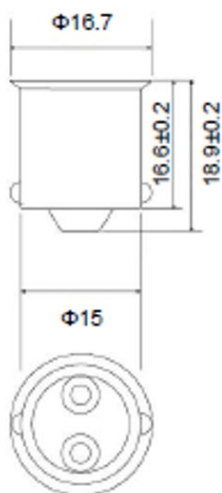

Unit: mm

Technical data

Lamp bulb type: BA15D

Material: Brass

Plating: Nickel

Voltage rating: 50 VAC/ 75 VDC max.

Operating temperature: -10 to 105 °C

Storage temperature: -10 to 85 °C

Max. power of lamp: 25 W