



Stack light siren element


VAZ- HORN-70MM-0..100DBA-8TONE

- Modular design
- Bayonet system for simple mounting and dismounting
- Volume adjustable
- 8 different tone options
- 70-mm-series

Stack light siren element 8 tone



Dimensions

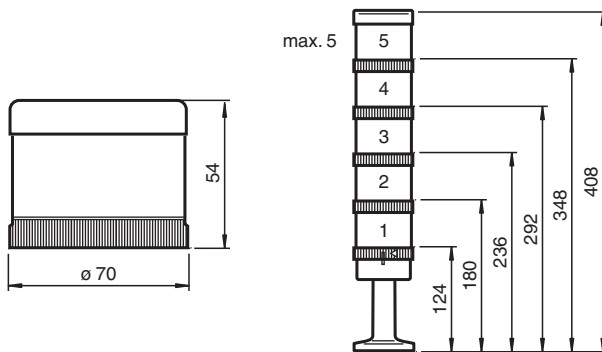

Technical Data

General specifications	
UL File Number	E223176
Color	black
Frequency	Approx. 900 Hz/2.8 kHz
Loudness	82 ... 102 dB
Functional safety related parameters	
MTTF _d	600 a
Electrical specifications	
Rated operating voltage	U _e 24 V AC/DC
Rated operating current	I _e ≤ 32 mA
Directive conformity	
Electromagnetic compatibility	
Directive 2014/30/EU	EN 60947-5-1:2004+A1:2009 EN 60947-1:2007
Standard conformity	
Degree of protection	EN 60529:2000
Ambient conditions	

Release date: 2022-06-30 Date of issue: 2022-06-30 Filename: 307857_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com


Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

pf PEPPERL+FUCHS



Technical Data

Ambient temperature	-20 ... 50 °C (-4 ... 122 °F)
Mechanical specifications	
Degree of protection	IP65
Connection	Bayonet system
Life span	min. 5000 hours

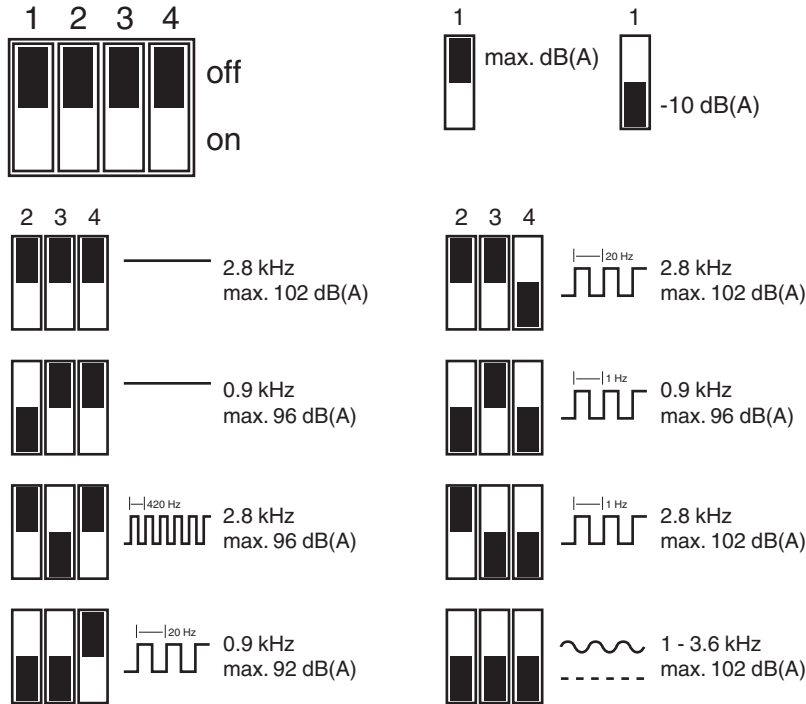Parameterization



Matching System Components

	VAZ-CLAMP-70MM-90°	Stack light terminal base with cover plate
	VAZ-70MM-IO	Signal tower connection element IO-Link with cover

Release date: 2022-06-30 Date of issue: 2022-06-30 Filename: 307857_eng.pdf