




## Stack light siren element VAZ-HORN-40MM-85DBA-2TONE

- Modular design
- Bayonet system for simple mounting and dismounting
- 2 different tone options
- 40-mm-series

Stack light siren element, 2 tones



### Dimensions

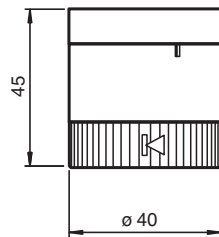

### Technical Data

General specifications			
Signal type		Continuous tone, pulse tone	
UL File Number		E223176	
Color		grey	
Frequency		2.9 kHz	
Loudness		85 dB	
Electrical specifications			
Rated operating voltage	U <sub>e</sub>	24 V AC/DC	
Rated operating current	I <sub>e</sub>	≤ 80 mA	
Inrush current		500 mA	
Ambient conditions			
Ambient temperature		-30 ... 60 °C (-22 ... 140 °F)	
Mechanical specifications			
Degree of protection		IP66	
Connection		Bayonet system	
Material		PC	
Mass		25 g	

Release date: 2022-06-30 Date of issue: 2022-06-30 Filename: 324828\_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group  
www.pepperl-fuchs.com

USA: +1 330 486 0001  
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111  
fa-info@de.pepperl-fuchs.com


Singapore: +65 6779 9091  
fa-info@sg.pepperl-fuchs.com

PEPPERL+FUCHS

### Technical Data

Life span min. 5000 hours

### Matching System Components

	<b>VAZ-CLAMP-40MM</b>	Stack light terminal base with cover plate
-----------------------------------------------------------------------------------	-----------------------	--------------------------------------------

Release date: 2022-06-30 Date of issue: 2022-06-30 Filename: 324828\_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group  
www.pepperl-fuchs.com

USA: +1 330 486 0001  
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111  
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091  
fa-info@sg.pepperl-fuchs.com