

VOLTCRAFT

DATASHEET

Item No.: 2632829

Type designation: LR20 Common: D

Chemical system: Alkaline


Nominal voltage: 1.5 V

Weight: Approximate 140.0 g

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Dimension (mm)

| / | min | max |
|--------|------|------|
| Φ | 32.3 | 34.2 |
| A | 59.5 | 61.5 |
| C | 18.0 | - |
| F | - | 9.5 |
| G | 1.5 | - |

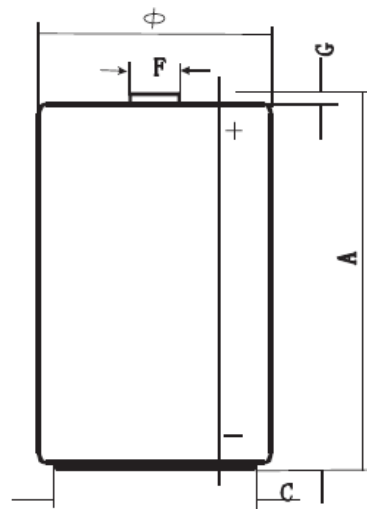

Capacity: 18000 mAh (25 mA, 24 h/d, 20°C, end voltage = 0.8 V)

Operating temperature: -18°C ~ 50°C

Recommend storage temperature: 20°C \pm 2°C

Shelf lifetime: 7 Years