

VOLTCRAFT

DATASHEET

Item No.: 2637992

Type designation: LR14 Common: C

Chemical system: Alkaline


Nominal voltage: 1.5 V

Weight: Approximate 70.0 g

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Dimension (mm)

/	min	max
Φ	24.9	26.2
A	48.6	50.0
C	13.0	-
F	-	7.5
G	1.5	-

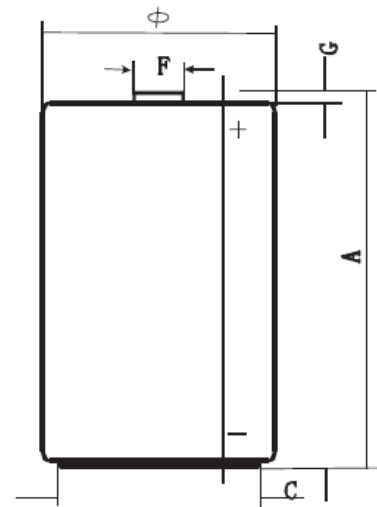

Capacity: 8000 mAh (25 mA, 24 h/d, 20°C, end voltage = 0.8 V)

Operating temperature: -18°C ~ 50°C

Recommend storage temperature: 20°C \pm 2°C

Shelf lifetime: 7 Years