




Data Sheet - TRU Components

BN: 2645197


Last updated: 3 Oct 2024

12A 300V Relay Socket

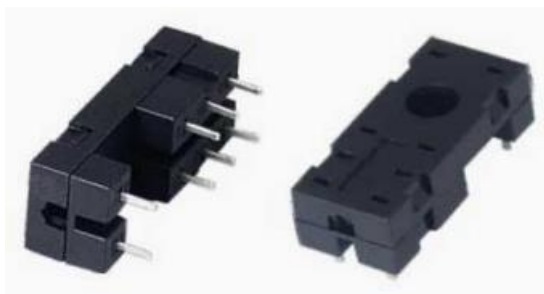


Drawing:

Outline dimensions(mm)

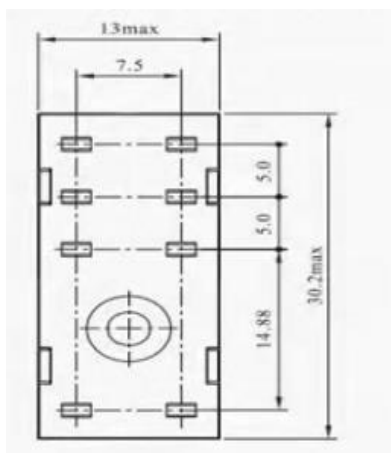

Mount dimensions(mm)

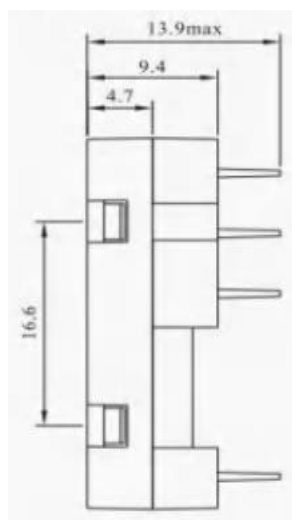

Technical data:

Voltage: 300V AC

Dielectric strength: 3000V/S

Current: max. 12A

Contact resistance: $\leq 50\text{M}\Omega$

Plastic material: PBT

Operating & Storage Temperature: $-40^{\circ}\text{C} \sim +70^{\circ}\text{C}$ (no icing)

Operating & Storage humidity: $<95\%\text{RH}$