



Passive Components > Resistors > Surface Mount Resistors



Resistor Type: **Precision Resistor**

Number of Terminations: **2**

Package Size Code: **0402**

Packaging Method: **Taped & Reeled**

Passive Component Tolerance: **.1 %**

Features

Product Type Features

Product Type	Fixed Resistor
Resistor Type	Precision Resistor
Package Size Code	0402
Element Type	Thin Film

Configuration Features

Number of Resistors	1
---------------------	---

Electrical Characteristics

Passive Component Tolerance	.1 %
Resistance Class	1kΩ – 1MΩ
Resistance Value	8.25K Ω
Power Rating	.063 W

Termination Features

Number of Terminations	2
Surface Mount Resistor Termination Type	Solder

Dimensions

Passive Component Dimensions	1 x .5 x .3 mm
------------------------------	----------------

Usage Conditions

Temperature Coefficient	±25 ppm/°C
-------------------------	------------



Packaging Features

Packaging Method	Taped & Reeled
------------------	----------------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2022 (224) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 260°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 TE Part # 3-1879216-5 CPF0402 200K 0.1% 25PPM 1K RL	 TE Part # 1-1879417-9 CPF 0603 1M0 0.1% 25PPM 1K RL	 TE Part # 1879417-8 CPF0603 1M0 0.1% 25PPM 5K RL	 TE Part # 1-1614959-4 CPF0805 2M0 0.1% 25PPM 1K RL
--	--	---	---



 TE Part # 9-1879216-1 CPF 0402 158K 0.1% 25PPM 5K RL	 TE Part # 9-1879211-3 CPF 0402 17K4 0.1% 25PPM 5K RL	 TE Part # 9-1879211-4 CPF 0402 17K8 0.1% 25PPM 5K RL	 TE Part # 1879211-5 CPF 0402 1K82 0.1% 25PPM 5K RL
 TE Part # 1879211-6 CPF 0402 1K87 0.1% 25PPM 5K RL	 TE Part # 1879211-7 CPF 0402 1K91 0.1% 25PPM 5K RL	 TE Part # 1879211-8 CPF 0402 1K96 0.1% 25PPM 5K RL	 TE Part # 3-1879211-7 CPF 0402 4K02 0.1% 25PPM 5K RL
 TE Part # 3-1879211-9 CPF 0402 4K22 0.1% 25PPM 5K RL	 TE Part # 4-1879211-0 CPF 0402 4K32 0.1% 25PPM 5K RL	 TE Part # 4-1879211-1 CPF 0402 4K42 0.1% 25PPM 5K RL	 TE Part # 4-1879211-2 CPF 0402 4K53 0.1% 25PPM 5K RL
 TE Part # 4-1879211-3 CPF 0402 4K64 0.1% 25PPM 5K RL	 TE Part # 4-1879211-4 CPF 0402 4K75 0.1% 25PPM 5K RL	 TE Part # 4-1879211-5 CPF 0402 4K87 0.1% 25PPM 5K RL	

Customers Also Bought

 TE Part #1-1623728-8 BCHE 11 W 3K3 5%	 TE Part #4-1622824-6 RL73H 3A R91 1% 4K RL	 TE Part #3-644615-2 02P MTA156 POL HDR ASSY LF	 TE Part #5-104549-3 24 SYS50 S/M HDR DRST SHRDSN
--	---	---	---






TE Part #1624112-2
3650 0603 12nH 5% 2K RL




TE Part #2-1879337-7
CPF 0603 4K64 1% 50PPM 1K RL




TE Part #2-1879214-4
CPF 0402 562R 0.1% 25PPM 1K RL

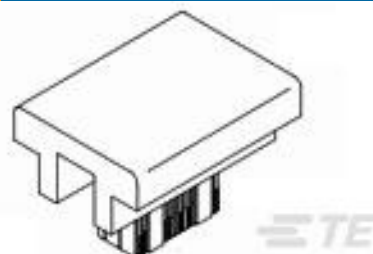

TE Part #91349-1
SEATING TOOL,HMZD HDR, 4 PAIR

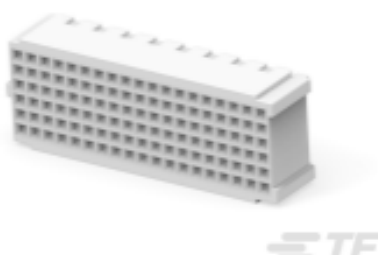

TE Part #2355825-1
Mezalok, Socket, 114 p, 10 mm, 50 Au,

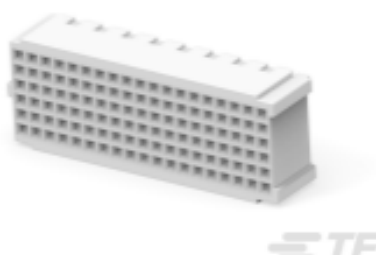

TE Part #2355825-3
Mezalok, Socket, 114 p, 12 mm, 50 Au

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_6-1879211-6_BA.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_6-1879211-6_BA.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_6-1879211-6_BA.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

CPF-1016

English