



Application Tooling > Spare & Wear Tooling



Applicator & Product Style: OCEAN

Features

Other

| | |
|----------------------------|-------|
| Applicator & Product Style | OCEAN |
|----------------------------|-------|

Product Compliance

For compliance documentation, visit the product page on TE.com>

| | |
|---|--|
| EU RoHS Directive 2011/65/EU | Out of Scope |
| EU ELV Directive 2000/53/EC | Out of Scope |
| China RoHS 2 Directive MIIT Order No 32, 2016 | Restricted Materials Above Threshold |
| EU REACH Regulation (EC) No. 1907/2006 | Current ECHA Candidate List: JUNE 2022 (224) Candidate List Declared Against: JAN 2022 (223) Does not contain REACH SVHC |
| Halogen Content | Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free |
| Solder Process Capability | Not applicable for solder process capability |

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts



TE Part # 87269-1
LOCKING CLIP CONT ASSY 31X62



TE Part # 5-87269-1
LOCKING CLIP CONT ASSY 31X62



TE Part # 87269-2
LOCKING CLIP CONT ASSY 31X62



CRIMPER REPRESENTATION ONLY
TE Part # 1-456404-0
CRIMPER WIRE .070 F



TE Part # 2-2836425-1
OCEAN_2.0_Applicator-S-070F1100



TE Part # 2-2836425-2
OCEAN_2.0_Applicator-S-070F1100A



TE Part # 2836425-1
OCEAN_2.0_Applicator-S-070F1100



TE Part # 2836425-2
OCEAN_2.0_Applicator-S-070F1100A



CRIMPER REPRESENTATION ONLY
TE Part # 3-1633966-8
CRIMPER,INSULATION O



CRIMPER REPRESENTATION ONLY
TE Part # 5-2119784-7
CRIMPER INSULATION O PREMIUM



ANVIL REPRESENTATION ONLY
TE Part # 6-1633919-2
ANVIL COMBINATION




TE Part # 7-2836425-1
OCEAN_2.0_Applicator-S-070F1100




TE Part # 7-2836425-2
OCEAN_2.0_Applicator-S-070F1100A

Customers Also Bought



TE Part #917067-6
040-2 TAB CONT S GOLD 22-18

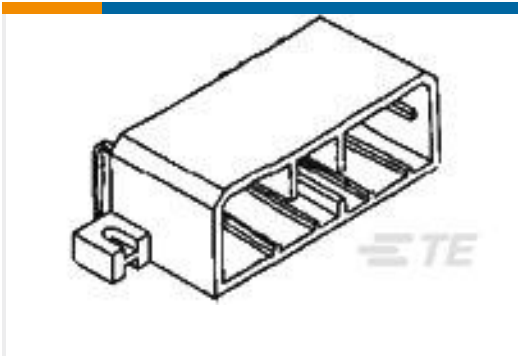

TE Part #173858-4
070 MULTILOCK CAP ASSY 12P GRN




TE Part #2151144-1
OCEAN_2.0_APPLICATOR-S-067F062F




TE Part #1333225-1
ANVIL, COMBINATION SPECIAL



TE Part #2-2119582-7
Crimper, Insulation F Premium

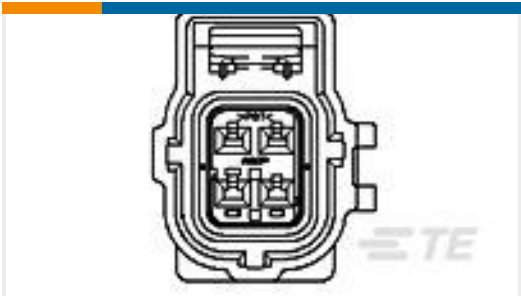

TE Part #184394-1
2X2 PLG ASY W/RET W/O CPA C3-A

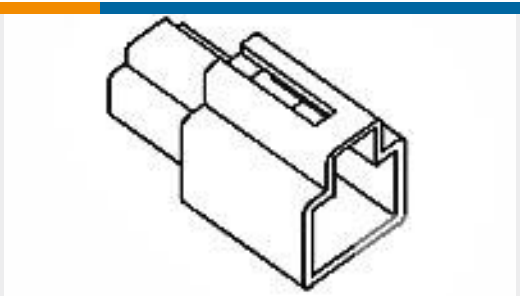

TE Part #172217-1
FF 250 REC HSG 2P NYLON NAT



TE Part #2-2151494-1
OCEAN_2.0_APPLICATOR-S-055F055F



TE Part #CP4904-000
ES2000-NO.1-C1-0-65MM-SH



TE Part #184328-1
2X2 CAP ASY KEY E C4

Documents

Product Drawings

OCEAN_2.0_SPARE_PART_KIT-070F110O

English

Instruction Sheets

Instruction Sheet (U.S.)

English