




## WORKLIGHT PD

Pendant light silver 57W 5000lm 4000K CRI80 80° DALI

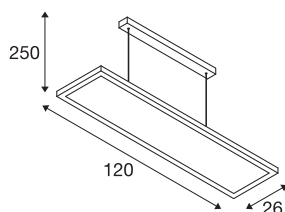

The silver WORKLIGHT PD can handle any requirements for modern workplace lighting. With an integrated LED light, 5000 lumen,  $UGR \leq 19$  and 4000 Kelvin, this aluminum pendant light emits a neutral white light, which is ideal for enhanced productivity. The light is already equipped with pendant suspensions and a ceiling rose and is thus ready for direct connection to a 200 V mains power supply. With an LED lifespan of 50,000 hours, it is also extremely sustainable.



## TECHNICAL DATA

Item no.	1006345
Number of different light outlets	2
IP Code	IP 20
Impact resistance class	IK 02
Impact resistance	0.2 Joule
Assembly	Surface
Assembly details	Ceiling
Dimmable	Yes
Dimming technology	DALI
Primary nominal voltage	200-240V ~50/60Hz
Secondary power / voltage	1550 mA
Safety class	I
Wattage	57 W
Minimum ambient temperature	-20 °C
Maximum ambient temperature	45 °C
Level of inrush current	5.1 A
Duration of inrush current	148 µs
Temperature at glass (light emission)	40 °C
Stroboscopic effect (SVM)	0.01
Lumen	5000 lm
Colour temperature	4000 Kelvin
Beam angle	80 °

## Light Source

916322	
916564	

Color	silver
CRI	80
UGR $\leq$	19
LXXBXX data	L80B10
Service life	50000 h
Risk Group	0
Length	120 cm
Width	26 cm
Height	3 cm
Pendant length	250 cm
Net weight	5.8 kg
Gross weight	6.206 kg