




## M-POL S Polehead

Shader lamp head, anthracite, 11W, 285/310lm, 2700/3000K, CRI90


Suitable for universal use, featuring a sophisticated design and high output: the lamp heads and diffusers in the first DALI-dimmable SLV outdoor family are ideal for a variety of applications. The cylindrical M-POL S Polehead has a CRI of over 90, 285 / 310 lumen, and an LED lifespan of 50,000 hours, which can satisfy the most challenging lighting design requirements. Use the appropriate lamp head to implement specific outdoor projects.

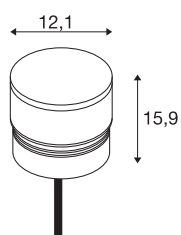

## TECHNICAL DATA

Item no.	1006387
IP Code	IP 65
Impact resistance class	IK 10
Assembly details	Ground with Acc.
Primary nominal voltage	220-240V ~50/60Hz
Secondary power / voltage	500
Wattage	11 W
Minimum ambient temperature	-20 °C
Maximum ambient temperature	35 °C
Level of inrush current	4.7 A
Duration of inrush current	30 µs
Stroboscopic effect (SVM)	0.01
Lumen	285 / 310 lm
Colour temperature	2700/3000 Kelvin
Color	anthracite
CRI	90
LXXBXX data	L80B50
Service life	50000 h
Risk Group	1
Height	15.9 cm
Diameter	12.09 cm
Net weight	1.052 kg

## Light Source

		Gross weight	1.126 kg
--	---	--------------	----------

## Accessories

1006379	M-POL 30 Pole , Bollard, anthracite, 23.4cm
1006380	M-POL 60 Pole , Bollard, anthracite, 53.4cm
1006381	M-POL 90 Pole , Bollard, anthracite, 83.4cm
1006382	M-POL ground anchor , stainless steel
228726	T-CONNECTION BOX , black, IP68
228730	CONNECTION BOX , 3-pin, IP68