




## M-POL S Polehead

Lamp head, anthracite, 19W, 890/950lm, 2700/3000K, CRI90, DALI

Suitable for universal use, featuring a sophisticated design and high output: the lamp heads and diffusers in the first DALI-dimmable SLV outdoor family are ideal for a variety of applications. With a CRI of over 90, 890 / 950 lumen, and an LED lifespan of 50,000 hours, the cylindrical M-POL S Polehead can satisfy even the most challenging requirements. Choose a specific lamp head as preferred for your lighting projects.

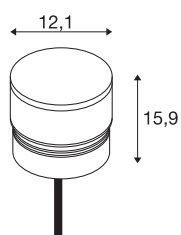

## TECHNICAL DATA

Item no.	1006389
IP Code	IP 65
Impact resistance class	IK 10
Assembly details	Ground with Acc.
Dimmable	Yes
Dimming technology	DALI
Primary nominal voltage	220-240V ~50/60Hz
Secondary power / voltage	500
Wattage	19 W
Minimum ambient temperature	-20 °C
Maximum ambient temperature	45 °C
Rated standby power	0.5 W
Level of inrush current	10 A
Duration of inrush current	30 µs
Stroboscopic effect (SVM)	0.01
Lumen	890 / 950 lm
Colour temperature	2700/3000 Kelvin
Color	anthracite
CRI	90
LXXBXX data	L80B50
Service life	50000 h
Risk Group	1

## Light Source



### Accessories

1006379	M-POL 30 Pole , Bollard, anthracite, 23.4cm
1006380	M-POL 60 Pole , Bollard, anthracite, 53.4cm
1006381	M-POL 90 Pole , Bollard, anthracite, 83.4cm
1006382	M-POL ground anchor , stainless steel
1006453	Connection box , 5-pin, IP68, black, DALI
228725	CONNECTION BOX , 5-pin, IP68

Height	16.4 cm
Diameter	12.09 cm
Net weight	1.148 kg
Gross weight	1.228 kg