




M-POL M Polehead

Lamp head, anthracite, 11W, 590/660lm, 2700/3000K, CRI90


Universal application and sophisticated design: the lamp heads in the DALI-dimmable SLV outdoor family are highly flexible. With a CRI of over 90, 590 / 660 lumen, and an LED lifespan of 50,000 hours, the cylindrical M-POL M Polehead lamp head can satisfy even the most challenging requirements. Enjoy the flexibility to implement a diverse range of lighting projects.

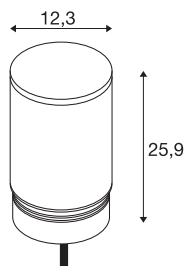

TECHNICAL DATA

Item no.	1006384
IP Code	IP 65
Impact resistance class	IK 10
Assembly details	Ground with Acc.
Primary nominal voltage	220-240V ~50/60Hz
Secondary power / voltage	500
Wattage	11 W
Minimum ambient temperature	-20 °C
Maximum ambient temperature	35 °C
Level of inrush current	4.7 A
Duration of inrush current	30 µs
Stroboscopic effect (SVM)	0.01
Lumen	590 / 660 lm
Colour temperature	2700/3000 Kelvin
Color	anthracite
CRI	90
LXXBXX data	L80B50
Service life	50000 h
Risk Group	1
Height	25.9 cm
Diameter	12.26 cm
Net weight	1.232 kg

Light Source

		Gross weight	1.318 kg
--	---	--------------	----------

Accessories

1006379	M-POL 30 Pole , Bollard, anthracite, 23.4cm
1006380	M-POL 60 Pole , Bollard, anthracite, 53.4cm
1006381	M-POL 90 Pole , Bollard, anthracite, 83.4cm
1006382	M-POL ground anchor , stainless steel
228726	T-CONNECTION BOX , black, IP68
228730	CONNECTION BOX , 3-pin, IP68