

800pcs 2:1 Heat shrink tube-assortment

Item No. : 1905CA055


This range is particularly suitable for hobbyists, craftsmen, field service, service workshops, electronics and the laboratory needs.

800 pieces of shrinking ration 2:1 standard shrinking tube for a range of application diameter from 1.5 to 12.0 mm.

The heat-shrink tubing can be used for insulation, protective covering of components, as anti-kink protection, protection against corrosion, as well as repair of cables and lines, and much more be used.



Shrinking ratio	2 : 1
Material	PE
Shrinking temperature	70°C - 110°C
Operation temperature	-40°C - 125°C
Flammability	VW-1
Tensile strength	≥ 10.4Mpa
Elongation at break	≥ 300%
Rated voltage	600V
Diselectric strength	≥ 1.5kv/mm at 30sec.
Volume resistivity	≥ 10 ¹⁴ Ω

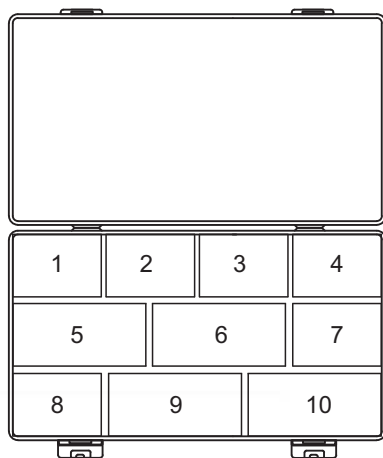

set contents

Section	Heat shrink tube		Length	pcs
	Inner diameter ø	after shrink ø		
1-2	1.5 mm	0.85 mm	45 mm	150
3-4	2.5 mm	1.3 mm	45 mm	110
5	3.5 mm	1.8 mm	65 mm	60
6	5.0 mm	2.5 mm	65 mm	30
7	6.0 mm	3.0 mm	45 mm	25
8	8.0 mm	4.0 mm	45 mm	55
9	9.0 mm	4.5 mm	65 mm	55
10	12.0 mm	6.0 mm	65 mm	55