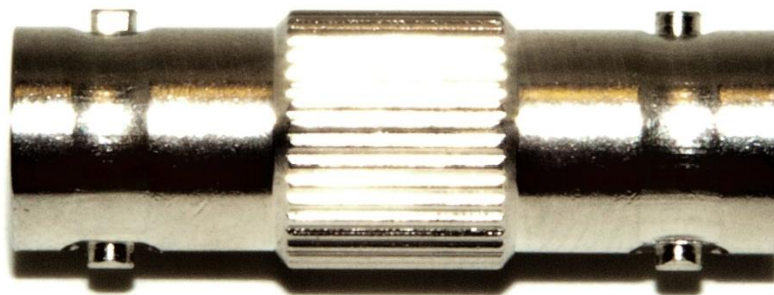


BU-P3283**(Adapter: BNC Female to Female)**

- The BU-P3283 is a female to female BNC adapter.
- Overall length 1.32" (33.5mm), OD = 0.49" (12.5mm)
- Material:

Body	Brass, tarnish-resistant plating
Center contact	Gold-plated beryllium copper
Dielectric	PTFE
- Ratings:

Impedance	50 Ohms
Voltage	30 VAC/60 VDC Max shield/earth 500VRMS inner conductor/shield
Temperature	-70°C to 170°C
- RoHS 3 compliant