

KERN PWS 3000-1

KERN

High-resolution precision balance made of stainless steel with IP protection



Category

Brand	KERN
Product category	Laboratory balance
Product group	Precision balance
Product family	PWS

Measuring System

Weighing system	Tuning fork
Number of weighing ranges	1
Weighing capacity [Max]	3200 g
Readability [d]	0,1 g
Reproducibility	0,1 g
Linearity	± 0,1 g
Resolution	32.000
Tare range	3200 g
Adjustment options	Adjusting with external weight
Recommended adjusting weight	3 kg (F1)
Stabilization time	3 s
Warm-up time	120 min
Eccentric loading at 1/3 [Max]	0,3 g
USP Minimum weight of sample (k = 2, U = 0.1%)	200 g
Construction type of the scale	Single-range balance

Units

kg
g
gn
dwt
tl (Tw)
tl (HK)
ozt
tl (Singap, Malays)
ct
lb

oz
tol
mom

Maximum creep (15 minutes)	400 mg
Maximum creep (30 minutes)	800 mg
Default unit	g

Display

Display type	LCD
Display backlight	✓
Display screen size	109×27 mm
Display digit height	16,5 mm
Languages of the user interface	Symbol language

Construction

Dimension housing (W×D×H)	310×205×85 mm
Dimensions completely mounted (W×D×H)	320×205×90 mm
Dimensions weighing surface (W×D)	190×190 mm
Dimensions weighing surface	190×190 mm
Material housing	stainless steel
Material weighing plate	stainless steel
Material platform	stainless steel
Level indicator	✓
Levelling feet adjustable	✓

Functions

PreTare function	✓
Recipe/summing level	Rez A (Net total)
Percentage determination	✓
Density determination	✓
Tolerance weighing	✓
Tolerance weighing - type of signal	acoustically visual
Underfloor weighing	Eye (optional)
Function for averaging under unstable weighing conditions	✓
Capacity - Display	✓
Counting function	✓
Counting resolution (laboratory conditions)	32.000
Counting reference weight can be entered	✓
Smallest piece weight when piece counting - laboratory conditions	100 mg
Smallest piece weight when piece counting - normal conditions	1 g
Reference quantity	5, 10, 30, 100

KERN PWS 3000-1



High-resolution precision balance made of stainless steel with IP protection

IP protection - complete device	IP65
Auto-off interval(s) in battery mode/rechargeable battery mode	3 min
Tare function	manual (multi)
Number of keys for operation	9

Interface

Interfaces	RS-232 standard
------------	-----------------

Power Supply

Supplied power supply	Power supply unit
Power supply type	Power adapter

Plug-in power supply / adapter for countries - included with the delivery	EURO AUS UK US CH
---	-------------------------------

Plug-in power supply / adapter for countries - optional	EURO AUS UK US CH
---	-------------------------------

Input voltage power supply / power [Max]	100 V - 240 V AC 50/60 Hz 0,3 A
--	---------------------------------

Power supply cable removable	removable
------------------------------	-----------

Input voltage device / power [Max]	5,95 V, 1 A
------------------------------------	-------------

Power socket for mains adapter	Hollow plug, inside plus, Ø outside 4,75 mm, Ø inside 1,7 mm, long 9,5 mm
--------------------------------	---

Battery / accumulator type	Alkali(-Manganese)
----------------------------	--------------------

Battery connection	Battery insert
--------------------	----------------

Environmental conditions

Ambient temperature [Min]	10 °C
---------------------------	-------

Ambient temperature [Max]	30 °C
---------------------------	-------

Humidity of environment [Max]	80 %
-------------------------------	------

Storage temperature [Min]	-20 °C
---------------------------	--------

Storage temperature [Max]	60 °C
---------------------------	-------

Approval

CE mark	✓
---------	---

Services (optional)

Article number for adjustment at the location of installation	961-247
---	---------

Article number for DAkkS calibration	963-127
--------------------------------------	---------

Article number for certificate of conformity	969-517
--	---------

Packing & Shipping


Delivery time	1 d
Dimensions packaging (W×D×H)	315×405×225 mm
Shipping method	Parcel service
Net weight approx.	3,0 kg
Gross weight approx.	4,2 kg
Shipping weight	5,7 kg

Product information

GTIN/EAN number	4045761311251
REACH classification	no prohibited substances

Pictograms

STANDARD

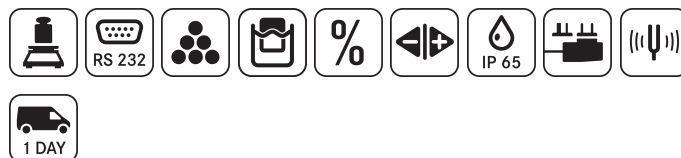

OPTION

