

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5055503420

Status:


Active

Overview:

SlimStack Board-to-Board/Board-to-FPC Connectors

Description:

SlimStack Board-to-Board Receptacle, 0.40mm Pitch, B8 Series, 0.80mm Mated Height, 2.50mm Mated Width, 34 Circuits

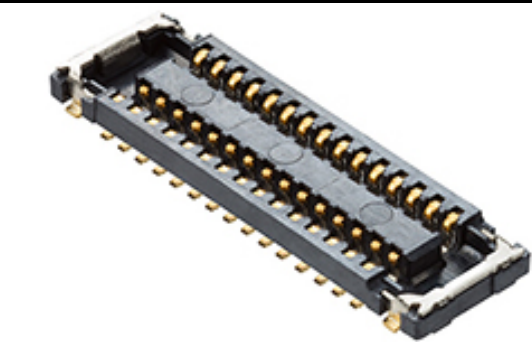

Series image - Reference only

Documents:	
3D Model	Datasheet (PDF)
Drawing (PDF)	Product Guide (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification 5055500000-002 (PDF)	Reference Guide (PDF)
Packaging Specification 5055509200-200 (PDF)	

General	
Product Family	PCB Receptacles
Series	505550
Application	Board-to-Board
Component Type	PCB Receptacle
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.4, B8
Taxonomy	Board-to-Board Connectors
UPC	191128261951
Physical	
Circuits (Loaded)	34
Circuits (maximum)	34
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Capable	No
Lock to Mating Part	Yes
Mated Height	0.80mm
Mated Width	2.50mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	22.698/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.40mm
Pitch - Termination Interface	0.40mm
Plating min - Mating	0.100µm
Plating min - Termination	0.050µm
Polarized to Mating Part	No
Polarized to PCB	No
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.3A
Voltage - Maximum	50V AC (RMS)/DC
Material Info	

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

505550 Series

Mates With

SlimStack B8 Plug 505551

Reference - Drawing Numbers

Packaging Specification	5055509200-200
Product Specification	5055500000-002
Sales Drawing	5055500000-000, 5055501000-001

This document was generated on 01/18/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION