

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0547220804

Status:

Active

Overview:


SlimStack Board-to-Board/Board-to-FPC Connectors

Description:

0.50mm Pitch SlimStack Receptacle, Surface Mount, Dual Row, Vertical, 1.50mm Stacking Height, Lower Circuit Size Version, 80 Circuits, Gold Plating with Nickel Barrier Plating Between Contact and Tail

Documents:	
Drawing (PDF)	Product Specification PS-54722-010-001 (PDF)
3D Model	Application Specification 547220000-A00 (PDF)
2D Drawing (DXF)	Packaging Specification SPK-54722-001-002 (PDF)
2D Drawing DXF (PDF)	Datasheet (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	PCB Receptacles
Series	54722
Application	Board-to-Board, Signal
Comments	Embossed Tape Reel Height: 380.00mm; Gold plating with Nickel plating between contact and tail
Component Type	PCB Receptacle
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.5, BB H1.5
Taxonomy	Board-to-Board Connectors
UPC	756054574393
Physical	
Circuits (Loaded)	80
Circuits (maximum)	80
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Capable	No
Lock to Mating Part	None
Mated Height	1.50mm
Mated Width	6.00mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	High Temperature Thermoplastic
Net Weight	228.601/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	None
PCB Thickness - Recommended	1.60mm
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.5A

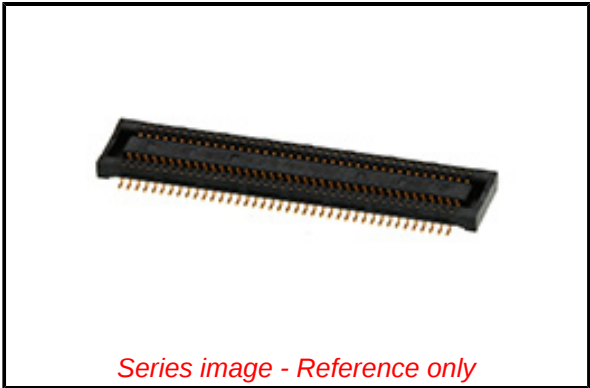

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

54722 Series

Mates With

55560 PCB Header

Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Application Specification	547220000-A00
Packaging Specification	SPK-54722-001-002
Product Specification	PS-54722-010-001
Sales Drawing	SD-54722-011-001, SD-54722-012-001

This document was generated on 01/18/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION