

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1042679617

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

0.50mm Pitch Easy-On FFC/FPC Wide Slim Connector, Right-Angle, ZIF, Surface Mount, Double Bottom Contact Style, 1.50mm Height, 96 Circuits

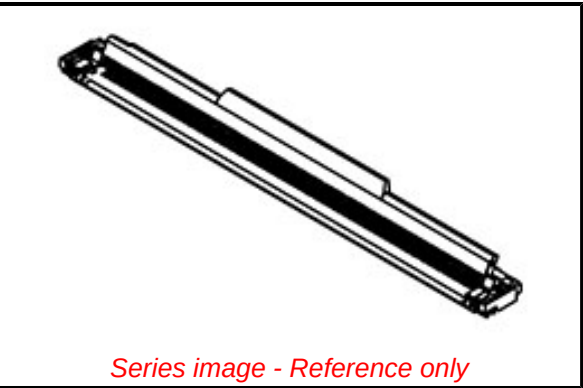

Documents:	
3D Model	Product Specification PS-104267-001-001 (PDF)
3D Model (PDF)	Packaging Specification SPK-104267-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	FFC/FPC Connectors
Series	104267
Comments	Black actuator
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
Taxonomy	FFC / FPC Connectors
UPC	889056496858
Physical	
Actuator Type	Front Flip
Circuits (Loaded)	96
Circuits (maximum)	96
Color - Resin	Natural
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	1.50mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	0.645/g
Number of Rows	1
Orientation	Right Angle
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Plating min - Mating	0.102µm
Plating min - Termination	0.051µm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-20° to +85°C
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SPK-104267-001-001
Product Specification	PS-104267-001-001
Sales Drawing	SD-104267-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

104267 Series

This document was generated on 01/02/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION