

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0533073071

Status:


Active

Overview:

SlimStack Board-to-Board/Board-to-FPC Connectors

Description:

SlimStack Board-to-Board Connector, 0.80mm Pitch, Plug, 4.50 or 5.50mm Mated Height, 30 Circuits, Vertical, without Boss

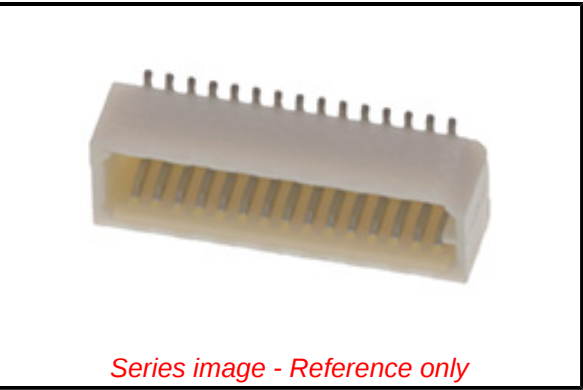

Series image - Reference only

Documents:

- 3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-52465-015-001 (PDF)

Product Specification PS-52588-031-001 (PDF)

Product Specification PS-52588-032-001 (PDF)
- Packaging Specification SPK-53307-001-001 (PDF)

Datasheet (PDF)

Product Guide (PDF)

RoHS Certificate of Compliance (PDF)

Reference Guide (PDF)

General

|                |                                                  |
|----------------|--------------------------------------------------|
| Product Family | PCB Headers                                      |
| Series         | 53307                                            |
| Application    | Board-to-Board, Signal                           |
| Component Type | PCB Header                                       |
| Overview       | SlimStack Board-to-Board/Board-to-FPC Connectors |
| Product Name   | SlimStack                                        |
| Series Name    | 0.8 and above                                    |
| Taxonomy       | Board-to-Board Connectors                        |
| UPC            | 822348180530                                     |

Physical

|                                |                                |
|--------------------------------|--------------------------------|
| Breakaway                      | No                             |
| Circuits (Loaded)              | 30                             |
| Circuits (maximum)             | 30                             |
| Color - Resin                  | Natural                        |
| First Mate / Last Break        | No                             |
| Glow-Wire Capable              | No                             |
| Guide to Mating Part           | No                             |
| Keying to Mating Part          | None                           |
| Lock to Mating Part            | None                           |
| Mated Height                   | 4.50mm, 5.50mm                 |
| Mated Width                    | 5.10mm, 7.20mm                 |
| Material - Metal               | Phosphor Bronze                |
| Material - Plating Mating      | Tin                            |
| Material - Plating Termination | Tin                            |
| Material - Resin               | High Temperature Thermoplastic |
| Net Weight                     | 407.100/mg                     |
| Number of Rows                 | 2                              |
| Orientation                    | Vertical                       |
| PCB Locator                    | No                             |
| PCB Retention                  | None                           |
| Packaging Type                 | Embossed Tape on Reel          |
| Pitch - Mating Interface       | 0.80mm                         |
| Pitch - Termination Interface  | 0.80mm                         |
| Plating min - Mating           | 3.048µm                        |
| Plating min - Termination      | 3.048µm                        |
| Polarized to PCB               | No                             |
| Shrouded                       | Fully                          |
| Temperature Range - Operating  | -40° to +105°C                 |
| Termination Interface: Style   | Surface Mount                  |

Electrical

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

|                 |               |
|-----------------|---------------|
| China ROHS      | Green Image   |
| ELV             | Not Relevant  |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

53307 Series

Mates With

Board-to-Board Receptacle [52465](#) , [52588](#)

|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 0.5A |
| Voltage - Maximum             | 50V  |

**Material Info**

**Reference - Drawing Numbers**

|                         |                                                         |
|-------------------------|---------------------------------------------------------|
| Packaging Specification | SPK-53307-001-001                                       |
| Product Specification   | PS-52465-015-001, PS-52588-031-001,<br>PS-52588-032-001 |
| Sales Drawing           | SD-53307-014-001, SD-53307-015-001                      |

This document was generated on 01/25/2023

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**