

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0533072671

Status:


Active

Overview:

SlimStack Board-to-Board/Board-to-FPC Connectors

Description:

SlimStack Board-to-Board Connector, 0.80mm Pitch, Plug, 4.50 or 5.50mm Mated Height, 26 Circuits, Vertical, without Boss

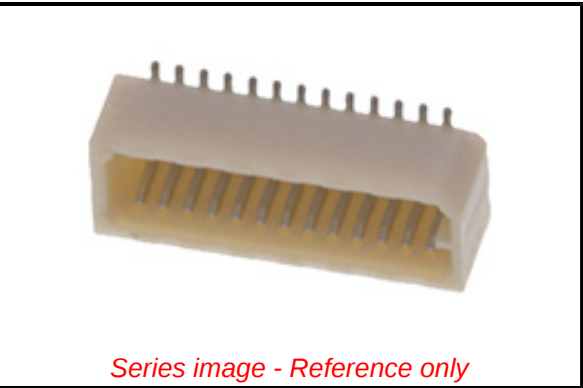

Series image - Reference only

Documents:	
3D Model (PDF)	Packaging Specification SPK-53307-001-001 (PDF)
3D Model	Datasheet (PDF)
Drawing (PDF)	Product Guide (PDF)
Product Specification PS-52465-015-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-52588-031-001 (PDF)	Reference Guide (PDF)

General	
Product Family	PCB Headers
Series	53307
Application	Board-to-Board, Signal
Component Type	PCB Header
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.8 and above
Taxonomy	Board-to-Board Connectors
UPC	822348180516
Physical	
Breakaway	No
Circuits (Loaded)	26
Circuits (maximum)	26
Color - Resin	Natural
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	None
Mated Height	4.50mm, 5.50mm
Mated Width	5.10mm, 7.20mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	358.600/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.80mm
Pitch - Termination Interface	0.80mm
Plating min - Mating	3.048µm
Plating min - Termination	3.048µm
Polarized to PCB	No
Shrouded	Fully
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.5A

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
53307 Series

Mates With
Board-to-Board Receptacle 52465 , 52588

Voltage - Maximum

50V

Material Info

Reference - Drawing Numbers

Packaging Specification

SPK-53307-001-001

Product Specification

PS-52465-015-001, PS-52588-031-001

Sales Drawing

SD-53307-014-001, SD-53307-015-001

This document was generated on 01/25/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION