

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2132260210

Status:


Active

Overview:

CLIK-Mate Wire-to-Board Connectors

Description:

1.50mm Pitch CLIK-Mate Wire-to-Board PCB Receptacle, Single Row, Surface Mount, Right-Angle, 0.10µm Gold (Au) Plating, 2 Circuits, Natural

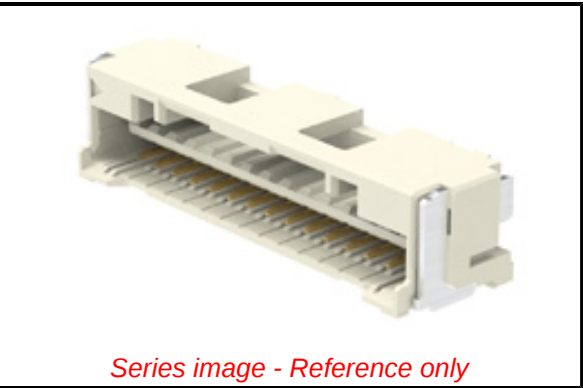

Documents:

[3D Model](#)

[3D Model \(PDF\)](#)

[Drawing \(PDF\)](#)

[Product Specification 5025780004-PS-000 \(PDF\)](#)

[Product Specification 5025781004-PS-000 \(PDF\)](#)

[Packaging Specification 2132269200-SPK-200 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	PCB Receptacles
Series	213226
Application	Signal, Wire-to-Board
Component Type	PCB Receptacle
Overview	CLIK-Mate Wire-to-Board Connectors
Product Name	CLIK-Mate
Taxonomy	PCB Headers and Receptacles
UPC	193264240883
Physical	
Circuits (Loaded)	2
Circuits (maximum)	2
Color - Resin	Natural
Durability (mating cycles max)	30
Glow-Wire Capable	No
Guide to Mating Part	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Resin	Polyamide
Net Weight	391.000/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.50mm
Pitch - Termination Interface	1.50mm
Plating min - Mating	0.102µm
Plating min - Termination	0.102µm
Polarized to Mating Part	Yes
Polarized to PCB	No
Stackable	No
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	2.0A
Voltage - Maximum	100V AC (RMS)/DC
Material Info	
Reference - Drawing Numbers	

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

213226 Series

Mates With

CLIK-Mate Housing [502578](#)

Packaging Specification
Product Specification
Sales Drawing

2132269200-SPK-200
5025780004-PS-000, 5025781004-PS-000
2132260000-SD-000

This document was generated on 01/27/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION