

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5024941070

Status:

Active

Overview:

CLIK-Mate Wire-to-Board Connectors

Description:

2.00mm Pitch CLIK-Mate Wire-to-Board PCB Receptacle, Single Row, Right-Angle, 10 Circuits

Documents:

Drawing (PDF)	Application Specification AS-502439-001-001 (PDF)
3D Model (PDF)	Application Specification AS-502439-002-001 (PDF)
3D Model	Packaging Specification 5024949200-200 (PDF)
Product Specification 5024431570-000 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

UL	E29179
----	--------

General

Product Family	PCB Receptacles
Series	502494
Application	Signal, Wire-to-Board
Component Type	PCB Receptacle
Overview	CLIK-Mate Wire-to-Board Connectors
Product Name	CLIK-Mate
Taxonomy	PCB Headers and Receptacles
UPC	822350937672


Physical

Circuits (Loaded)	10
Circuits (maximum)	10
Durability (mating cycles max)	30
Glow-Wire Capable	No
Guide to Mating Part	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Mated Height	6.90mm
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1050.000/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Plating min - Mating	2.032µm
Plating min - Termination	1.016µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Stackable	No
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	3.0A
Voltage - Maximum	250V AC (RMS)/DC

Material Info

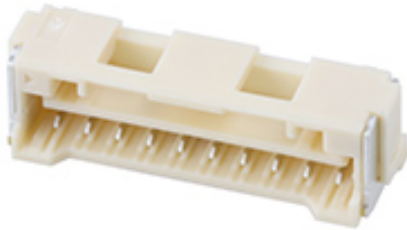

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

502494 Series

Mates With

502439 Crimp Housing

Reference - Drawing Numbers

Application Specification	AS-502439-001-001, AS-502439-002-001
Packaging Specification	5024949200-200
Product Specification	5024431570-000
Sales Drawing	5024941509-000, 5024941570-000

This document was generated on 01/30/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION