

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0536270274

Status:


Active

Overview:

SlimStack Board-to-Board/Board-to-FPC Connectors

Description:

SlimStack Board-to-Board Connector, 0.635mm Pitch, 0.635 Series, Plug, 10.00 or 16.00mm Mated Height, 6.40mm Mated Width, 20 Circuits

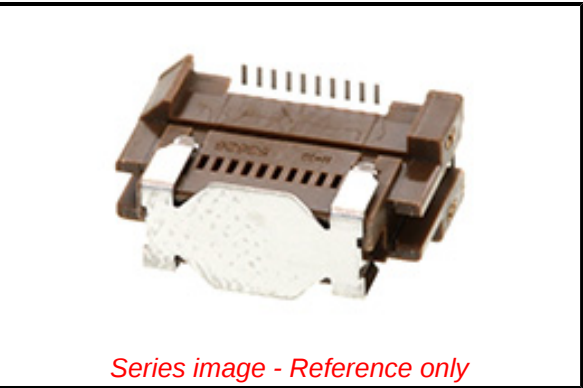

Documents:	
Drawing (PDF)	Datasheet (PDF)
3D Model (PDF)	Product Guide (PDF)
3D Model	RoHS Certificate of Compliance (PDF)
Product Specification 527600000-000 (PDF)	Reference Guide (PDF)
Packaging Specification SPK-53627-001-001 (PDF)	

Agency Certification	
UL	E29179
General	
Product Family	PCB Headers
Series	53627
Application	Board-to-Board, Signal
Comments	Stacking-Type
Component Type	PCB Header
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.635, Rigid
Taxonomy	Board-to-Board Connectors
UPC	822348164493
Physical	
Breakaway	No
Circuits (Loaded)	20
Circuits (maximum)	20
Color - Resin	Brown
Durability (mating cycles max)	50
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Mated Height	10.00mm, 16.00mm
Mated Width	6.40mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Net Weight	579.461/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	Yes
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.635mm
Polarized to PCB	Yes
Robotic Placement	Metal Cap
Shrouded	Fully
Temperature Range - Operating	-55° to +105°C
Termination Interface: Style	Surface Mount

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

53627 Series

Mates With

SlimStack 0.635 Receptacle 52885 , 52901

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	100V

Material Info

Reference - Drawing Numbers

Packaging Specification	SPK-53627-001-001
Product Specification	527600000-000
Sales Drawing	SD-53627-001-001, SD-53627-002-001

This document was generated on 02/07/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION