

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0347290201

Status:

Active

Overview:

Stac64 Single, Multi-Pocket and Hybrid Header System

Description:

Stac64 Receptacle Housing, 20 Circuits, Dual Row, Polarization B, Gray, Tray

Documents:

3D Model (PDF)

Application Specification AS-34729-020-001 (PDF)

Drawing (PDF)

Packaging Specification PK-31301-201-001 (PDF)

3D Model


Brochure (PDF)

Product Specification PS-34729-020-001 (PDF)

RoHS Certificate of Compliance (PDF)

Application Specification 347290200-AS-CH-000 (PDF)

|                               |                                                      |
|-------------------------------|------------------------------------------------------|
| General                       |                                                      |
| Product Family                | Crimp Housings                                       |
| Series                        | 34729                                                |
| Application                   | Automotive, Signal, Wire-to-Board                    |
| Overview                      | Stac64 Single, Multi-Pocket and Hybrid Header System |
| Polarization                  | B                                                    |
| Product Name                  | Stac64                                               |
| Taxonomy                      | Connector Housings                                   |
| UPC                           | 884982006553                                         |
| Physical                      |                                                      |
| Circuits (maximum)            | 20                                                   |
| Color - Resin                 | Gray                                                 |
| Gender                        | Receptacle                                           |
| Glow-Wire Capable             | No                                                   |
| Keying to Mating Part         | None                                                 |
| Lock to Mating Part           | Yes                                                  |
| Material - Resin              | High Temperature Thermoplastic                       |
| Net Weight                    | 7.530/g                                              |
| Number of Rows                | 2                                                    |
| Packaging Type                | Tray                                                 |
| Panel Mount                   | N/A                                                  |
| Pitch - Mating Interface      | 2.54mm                                               |
| Pitch - Termination Interface | 2.54mm                                               |
| Polarized to Mating Part      | Yes                                                  |
| Stackable                     | Yes                                                  |
| Temperature Range - Operating | -40° to +100°C                                       |
| Electrical                    |                                                      |
| Current - Maximum per Contact | 10.0A                                                |
| Solder Process Data           |                                                      |
| Lead-freeProcess Capability   | N/A                                                  |
| Material Info                 |                                                      |
| Reference - Drawing Numbers   |                                                      |
| Application Specification     | 347290200-AS-CH-000, AS-34729-020-001                |
| Packaging Specification       | PK-31301-201-001                                     |
| Product Specification         | PS-34729-020-001                                     |
| Sales Drawing                 | SD-34729-020-001                                     |

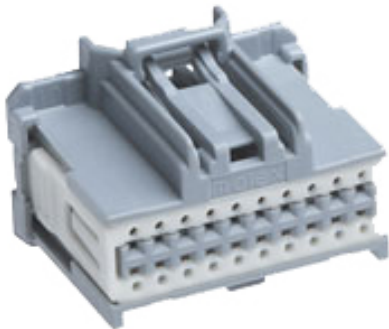

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

D(2022)4187-DC (10

June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

34729 Series

Mates With

34690 2.54mm Pitch Stac64 Vertical Header, 34691 2.54mm Pitch Stac64 Right Angle Header

Use With

34803 CTX64 Female Terminal

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**