


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0765605108](#)
Status: **Active**
Overview: [Impact Backplane Connector and Cable Assembly System](#)
Description: Impact 100 Ohm 6 Pair RAM Right-Angle Header, Right Guided, Open Endwall, 10 Columns, 180 Circuits, Pin Length 5.50mm, Plated Through Hole Dimension 0.39mm, Lead-Free

Documents:
[3D Model](#) [Application Specification AS-76060-9999-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Packaging Specification PK-70873-777-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Symbol Footprint Data SYM-76560-5108-001 \(PDF\)](#)
[Product Specification PS-76060-999-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Application Specification AS-76060-990-001 \(PDF\)](#)

Agency Certification	
UL	E29179
General	
Product Family	Backplane Connectors
Series	76560
Application	Coplanar
Application Tooling Documents	TM-622018799-001
Component Type	PCB Header
Data Rate	25.0 Gbps
Overview	Impact Backplane Connector and Cable Assembly System
Product Name	Impact
Taxonomy	Backplane Connectors
UPC	884982480681
Physical	
Circuits (Loaded)	180
Circuits (maximum)	180
Color - Resin	Black
Durability (mating cycles max)	200
First Mate / Last Break	No
Flammability	94V-0
Guide to Mating Part	Yes
Keying to Mating Part	None
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	32.008/g
Number of Columns	10
Number of Pairs	6
Number of Rows	18
Orientation	Right Angle
PC Tail Length	1.20mm
PCB Locator	No
PCB Retention	Yes
PCB Thickness - Recommended	1.00mm
Packaging Type	Tray
Pitch - Mating Interface	1.90mm
Pitch - Termination Interface	1.90mm
Plating min - Mating	0.762µm
Stackable	No

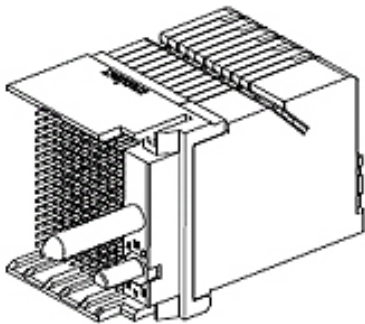

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2022)4187-DC (10 June 2022) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[76560](#) Series

Mates With
[76150](#) Impact 100 Ohm Daughtercard

Temperature Range - Operating	-55° to +85°C
Termination Interface: Style	Through Hole - Compliant Pin
Electrical	
Current - Maximum per Contact	0.75A
Impedance	100Ω
Shield Type	N/A
Shielded	No
Voltage - Maximum	30V AC (RMS)/DC
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-76060-990-001, AS-76060-9999-001
Electrical Model Document	EE-76560-0001-001
Packaging Specification	PK-70873-777-001
Product Specification	PS-76060-999-001
S-Parameter Model	SP-76560-0001-001, SP-76560-002-002
Sales Drawing	SD-76560-9004-001
Symbol/Footprint Data	SYM-76560-5108-001

This document was generated on 12/31/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION